
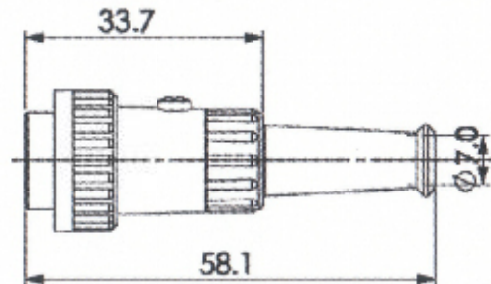
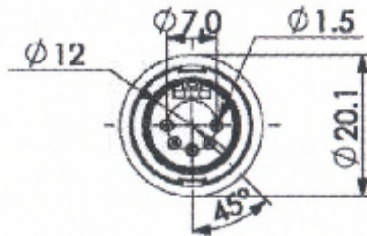


Datenblatt

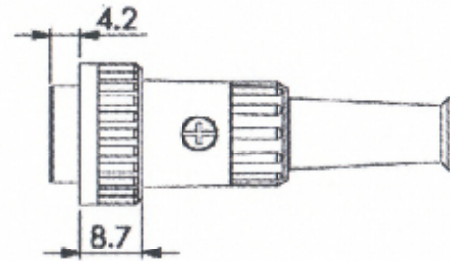

7	Terminals	Brass	Silver Ptd.	5
6	5P180 Housing	PBT		1
5	Strain Boot	PVC		1
4	Setscrew	Steel	Nickel Ptd.	1
3	"T" Holder	Steel	Nickel Ptd.	1
2	YE-139X Cap	Zn Alloy	Nickel Ptd.	1
1	YE-139X Cover	Zn Alloy	Nickel Ptd.	1
No.	Description	Material	Treat	Q'ty

Specifications

rating :

100V AC 4A MAX

contact resistance :

pins-30mΩ MAX; shell-50mΩ MAX

Insulation resistance :

MIN 100 MEGΩ @500V DC

voltage withstand :

250V AC R.M.S. for 1 minute