


Riing Plus 20 RGB Case Fan TT Premium Edition

• Features

- 12 sets separately controlled addressable LEDs
- Patented Riing Plus RGB Software Enabled
- Supports up to 16 controllers (maximum 80 fans)
- 16.8 million color RGB spectrum
- 11-blade high static pressure fan design for radiator cooling
- Long life hydraulic bearing for silent operation

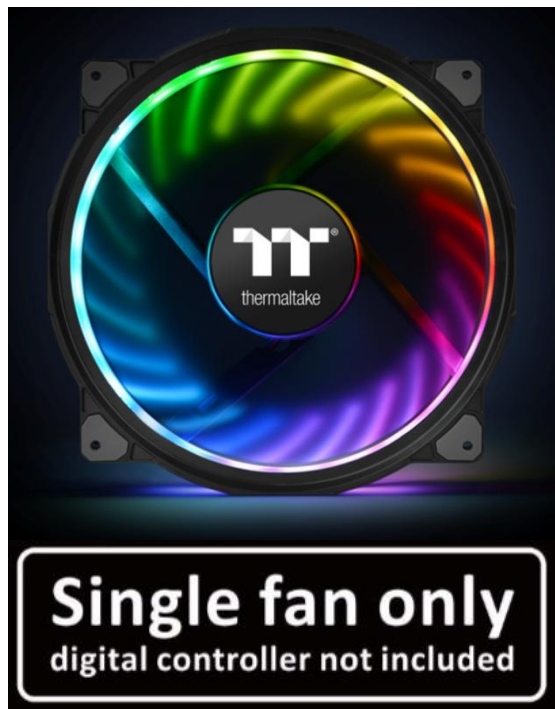

• Specification



P/N	CL-F070-PL20SW-A (Fan x1)
Fan Dimension	200 x 200 x 30 mm
Interface	USB 2.0 connectors (9 Pin)
System compatibility	Windows 7 / 8 / 8.1 / 10
Fan Started Voltage	9.0 V
Fan Rated Voltage	12 V & 5V
Rated Current	Fan 0.28 A (one fan)
Power Input	12V – 3.36 W . 5V – 4.25 W (Fan*1)
Fan Speed	500 ~ 1000 R.P.M
Max. Air Pressure	1.68 mm-H2O
Max. Air Flow .	117.96 CFM
Noise Level	29.2 dB-A
Bearing Type	Hydraulic Bearing
Life expectation	40,000 hrs,25°C
Weight	343 g

Riing Plus 20 RGB Case Fan TT Premium Edition

•Angle View



Front view



Back view



Unique Fan blade shape



Parts (M3 for Radiator
T5x10 fan screw)

Riing Plus 20 RGB Case Fan TT Premium Edition

• Detail Features

It only works with Riing Plus digital controller



Riing RGB software

Digitally controlled with
Riing RGB software



16.8 million colors

design for radiator cooling



Application

Support up to 80 pcs fans


Riing Plus 20 RGB Case Fan TT Premium Edition

•Angle View

It only works with Riing Plus digital controller




RGB Spectrum Mode:
A gorgeous and seamless transition through the entire range of 16.8 million RGB colors

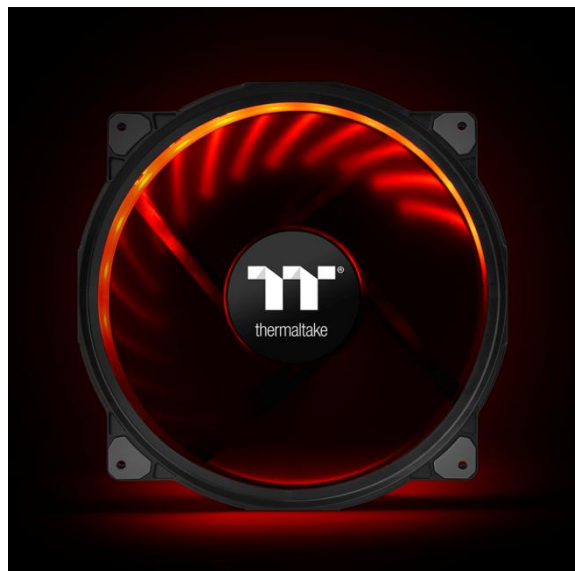

Ripple Mode:
RGB Colors ripple out across the fan



Flow Mode:
RGB or Single color flow in a clockwise direction

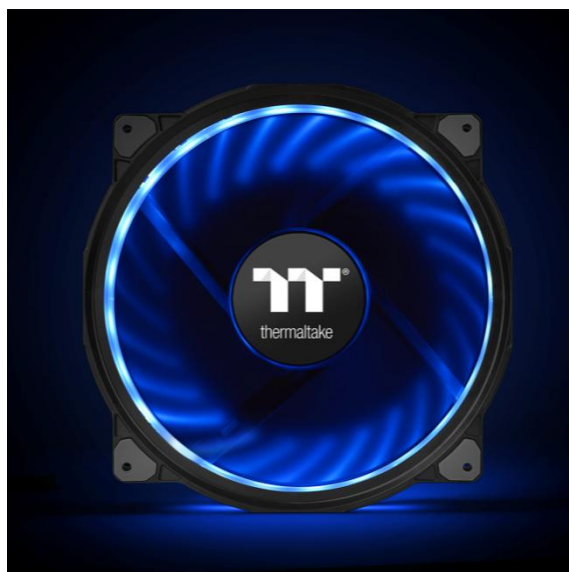

Pulse Mode:
A slow fade in and fade out of your color choice

Riing Plus 20 RGB Case Fan TT Premium Edition

P/N: CL-F070-PL20SW-A

Riing Plus 20 RGB Case Fan TT Premium Edition

Single fan only
digital controller not included

Patented 16.8 million
colors



TT thermaltake