

Thermaltake Riing 12 RGB Sync Edition 3 Pack

• Features

- Support MB RGB LED 12V Sync, ASUS, Gigabyte, MSI, Asrock, Biostar
- Patented circular LED bar
- 256 colors customized LED lighting effect
- High static pressure design for radiator cooling
- Anti-vibration mounting system
- Long life hydraulic bearing for reliable and silent operation

• Specification



P/N	CL-F071-PL12SW-A
Fan Dimension	120 x 120 x 25 mm
Started Voltage	9.0 V
Rated Voltage	12 V
Rated Current	0.2 A
Power Input	2.4 W
Fan Speed	800 ~ 1500 R.P.M
Max. Air Pressure	0.57 ~ 2.01 mm-H2O
Max. Air Flow	22.14 ~ 40.6 CFM
Noise Level	18.5 ~ 26.4 dB-A
BeaRiing Type	Hydraulic Bearing
Life expectation	40,000 hrs,25°C
Connector	12 V RGB header – 4Pin 2510 - 4Pin
Weight	163 g

Thermaltake Riing 12 RGB Sync Edition 3 Pack

•Angle View



Front view




Back view



Unique Fan blade shape



Side view

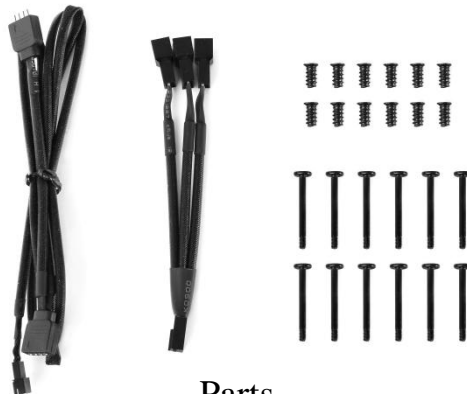

Parts

(M3 for Radiator 、 T5x10 fan screw 、 Motherboard Sync Cable 、 PWM Cable)

Thermaltake Riing 12 RGB Sync Edition 3 Pack

• Detail Features



Anti-vibration mounting system


Reduce vibrations between fan and chassis

Mainboard Synchronize

Designed to synchronize , ASUS, Gigabyte, MSI, Asrock, Biostar



•only support the motherboards with onboard 12 V RGB header

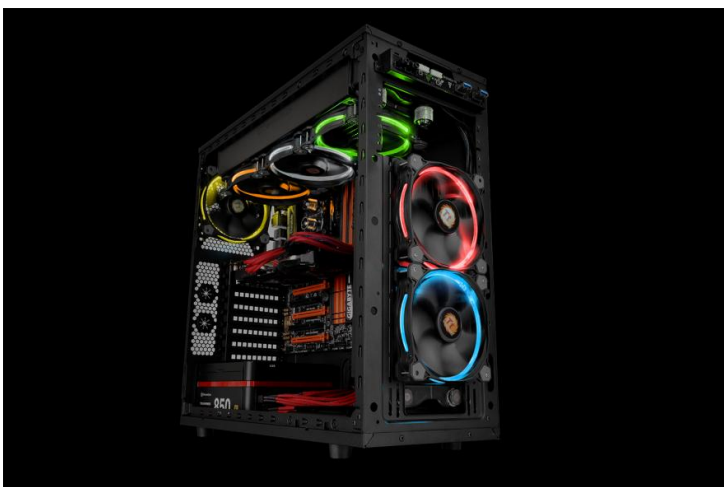

Application

To provide the best cooling solution inside your chassis

Thermaltake Riing 12 RGB Sync Edition 3 Pack

P/N: CL-F071-PL12SW-A

Riing 12 RGB Sync Edition 3 Pack

High Air Pressure Radiator



Tt **Thermaltake**
COOL *all* YOUR LIFE