

02 0250



Quicklock circular connectors, IP67



Quicklock plug, IP67, size 12, straight version, with plastic housing and solder terminals

Approvals:  pending 

02 0250

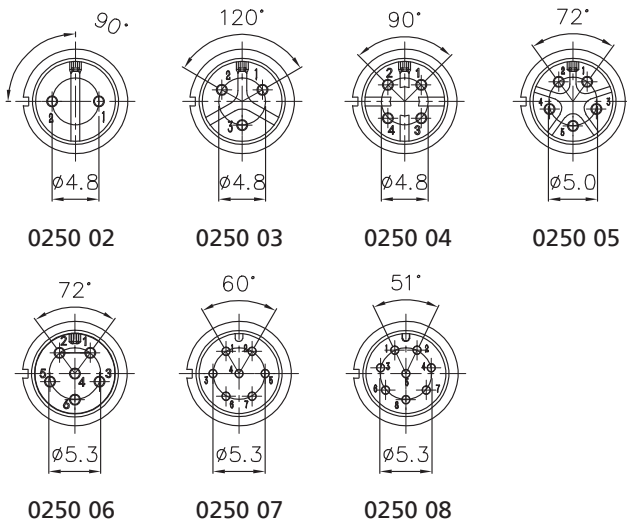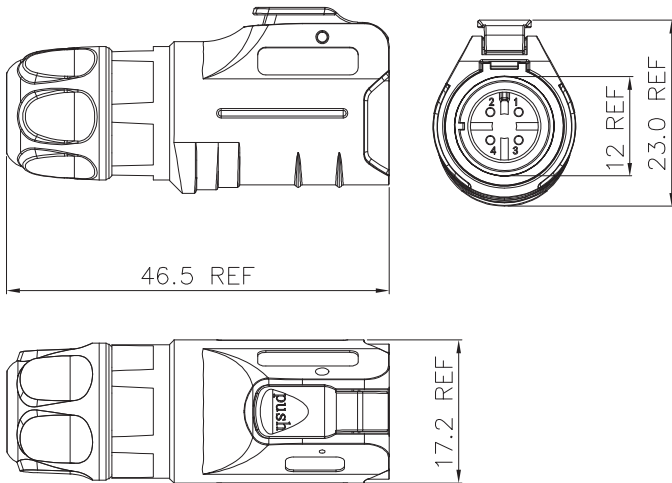

Environmental conditions

Temperature range -40 °C/+80 °C

Materials

Insulating body/handle PBT, V-0 according to UL94
Contact pin CuZn, gold-plated
Locking Zn-alloy, chrome-plated
Cap nut PBT, V-0 according to UL94

Mechanical data

Protection class IP67

Connectable conductors for solder area

Cable diameter 3.0–6.0 mm

Electrical data (at T_{amb} 20 °C)

Contact resistance ≤ 10 m Ω
Rated current 5 A (2–6 poles)
3 A (7–8 poles)
Rated voltage 125 V
Rated impulse voltage 1500 V AC
Creepage distance $\geq 1,5$ mm
Clearance $\geq 0,5$ mm
Insulation resistance > 500 M Ω

Associated products

Counterparts
☞ 0260 ☞ 0270

02 0250

Designation	Pole Number	PU (Pieces)	MDQ (Pieces)
0250 02	2	15	60
0250 03	3	15	60
0250 04	4	15	60
0250 05	5	15	60
0250 06	6	15	60
0250 07	7	15	60
0250 08	8	15	60

Packaging:

in individual plastic bags, in a cardboard box