

**FF 65 54/230V GY****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com



The filter fans combine a safe and profitable cabinet cooling due to their low energy consumption by maximum air flow. The fluted filter mat of the IP 55 version extends the service life by up to 300% in comparison to conventional filter mats.

**General ordering data**

Type	FF 65 54/230V GY
Order No.	<a href="#">2556870000</a>
Version	Filter fan, 230 V, 230 V, IP54, grey
GTIN (EAN)	4050118567496
Qty.	1 pc(s).

## FF 65 54/230V GY

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

## Technical data

## Dimensions and weights

Width	320 mm	Width (inches)	12.598 inch
Height	320 mm	Height (inches)	12.598 inch
Depth	157 mm	Depth (inches)	6.181 inch
Net weight	3,200 g		

## General data

EMC version	No	Filter class	G 4
Height of installation cut-outs	291 mm	Mounting depth	140 mm
Mounting height	7 mm	Noise emission	54 dB (A)
Rated AC voltage	230 V AC	Supply voltage, max	230 V
Supply voltage, min.	230 V	Type of connection	Spring contact
Type of mounting	Snap-on	Volume flow, free-blowing	480 m <sup>3</sup> /h
Width of installation cut-outs	291 mm	With filter	Yes

## Classifications

ETIM 6.0	EC000320	eClass 6.2	27-18-07-16
eClass 9.1	27-18-07-16		

## Approvals

Approvals




ROHS Conform

## Downloads

Approval/Certificate/Document of Conformity	<a href="#">EU Declaration of Conformity</a>
Engineering Data	<a href="#">STEP</a>

**Graph**

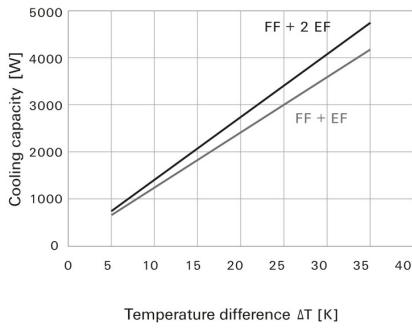

**Graph**

