

**RFF 605 54/230V GY****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com



The filter fans combine a safe and profitable cabinet cooling due to their low energy consumption by maximum air flow. The fluted filter mat of the IP 55 version extends the service life by up to 300% in comparison to conventional filter mats.

**General ordering data**

Type	RFF 605 54/230V GY
Order No.	<a href="#">2557730000</a>
Version	Filter fan, 230 V, 230 V, IP54, grey
GTIN (EAN)	4050118568370
Qty.	1 pc(s).

## RFF 605 54/230V GY

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

## Technical data

## Dimensions and weights

Width	436 mm	Width (inches)	17.165 inch
Height	436 mm	Height (inches)	17.165 inch
Depth	430 mm	Depth (inches)	16.929 inch
Net weight	4,800 g		

## General data

EMC version	No	Filter class	G 3
Height of installation cut-outs	291 mm	Mounting depth	34 mm
Mounting height	72 mm	Noise emission	67 dB (A)
Rated AC voltage	230 V AC	Supply voltage, max	230 V
Supply voltage, min.	230 V	Type of connection	Terminal strip
Type of mounting	Snap-on	Volume flow, free-blowing	350 m <sup>3</sup> /h
Width of installation cut-outs	291 mm	With filter	Yes

## Classifications

ETIM 6.0	EC000320	eClass 6.2	27-18-07-16
eClass 9.1	27-18-07-16		

## Approvals

Approvals



ROHS Conform

## Downloads

Approval/Certificate/Document of Conformity	<a href="#">EU Declaration of Conformity</a>
Engineering Data	<a href="#">STEP</a>


**Data sheet**

**RFF 605 54/230V GY**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com

**Drawings**

**Graph**

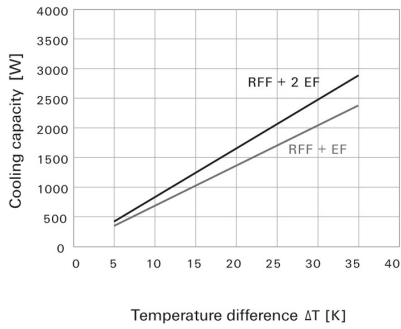

**Graph**

