

**FF 67 54/230V BK****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

**Similar to illustration**

The filter fans combine a safe and profitable cabinet cooling due to their low energy consumption by maximum air flow. The fluted filter mat of the IP 55 version extends the service life by up to 300% in comparison to conventional filter mats.

**General ordering data**

Type	FF 67 54/230V BK
Order No.	<a href="#">2556960000</a>
Version	Filter fan, 230 V, 230 V, IP54, black
GTIN (EAN)	4050118567588
Qty.	1 pc(s).

**Data sheet**

**FF 67 54/230V BK**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com

**Technical data**

**Dimensions and weights**

Width	320 mm	Width (inches)	12.598 inch
Height	320 mm	Height (inches)	12.598 inch
Depth	157 mm	Depth (inches)	6.181 inch
Net weight	3,700 g		

**General data**

EMC version	No	Filter class	G 4
Height of installation cut-outs	291 mm	Mounting depth	150 mm
Mounting height	7 mm	Noise emission	66 dB (A)
Rated AC voltage	230 V AC	Supply voltage, max	230 V
Supply voltage, min.	230 V	Type of connection	Spring contact
Type of mounting	Snap-on	Volume flow, free-blowing	845 m <sup>3</sup> /h
Width of installation cut-outs	291 mm	With filter	Yes

**Classifications**

ETIM 6.0	EC000320	eClass 6.2	27-18-07-16
eClass 9.1	27-18-07-16		

**Approvals**

Approvals



ROHS Conform

**Downloads**


Approval/Certificate/Document of Conformity	<a href="#">EU Declaration of Conformity</a>
Engineering Data	<a href="#">STEP</a>

**FF 67 54/230V BK**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com

**Drawings**

**Graph**

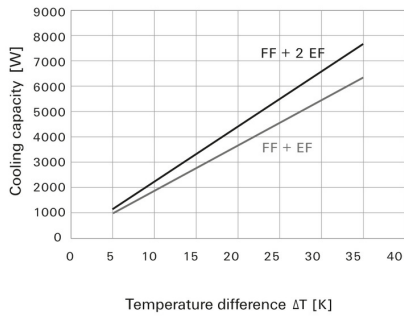

**Graph**

