

**RH-CBCO 100W 110-250V****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

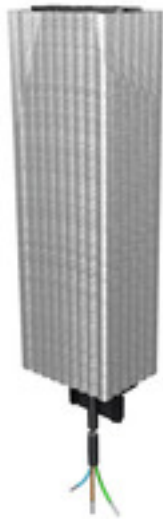
D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

**Similar to illustration**

The formation of condensation is one of the largest dangers for electrical cabinets. With our cabinet heaters prevention of condensation in the cabinet is guaranteed.

**General ordering data**

Type	RH-CBCO 100W 110-250V
Order No.	<a href="#">2557940000</a>
Version	Radiant heating panel, 110 V, 250 V, silver
GTIN (EAN)	4050118568585
Qty.	1 pc(s).

**RH-CBCO 100W 110-250V****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

**Technical data****Dimensions and weights**

Width	70 mm	Width (inches)	2.756 inch
Height	175 mm	Height (inches)	6.89 inch
Depth	50 mm	Depth (inches)	1.969 inch
Net weight	510 g		

**General data**

Continuous heat output at 10°C	100 W	Supply voltage, max	250 V
Supply voltage, min.	110 V	Type of connection	Pre-assembled cable
Type of mounting	Rail	With room thermostat	No

**Classifications**

ETIM 6.0	EC000737	eClass 6.2	27-18-07-16
eClass 9.1	27-18-07-10		

**Approvals**

Approvals



ROHS

Conform

**Downloads**

Approval/Certificate/Document of Conformity	<a href="#">EU Declaration of Conformity</a>
Engineering Data	<a href="#">STEP</a>