

**FF 11 54/230V BK****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com



The filter fans combine a safe and profitable cabinet cooling due to their low energy consumption by maximum air flow. The fluted filter mat of the IP 55 version extends the service life by up to 300% in comparison to conventional filter mats.

**General ordering data**

Type	FF 11 54/230V BK
Order No.	<a href="#">2556590000</a>
Version	Filter fan, 230 V, 230 V, IP54, black
GTIN (EAN)	4050118567212
Qty.	1 pc(s).

## FF 11 54/230V BK

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

## Technical data

## Dimensions and weights

Width	109 mm	Width (inches)	4.291 inch
Height	109 mm	Height (inches)	4.291 inch
Depth	62 mm	Depth (inches)	2.441 inch
Net weight	545 g		

## General data

EMC version	No	Filter class	G 3
Height of installation cut-outs	92 mm	Mounting depth	62 mm
Mounting height	4 mm	Noise emission	33 dB (A)
Rated AC voltage	230 V AC	Supply voltage, max	230 V
Supply voltage, min.	230 V	Type of connection	Pre-assembled cable
Type of mounting	Snap-on	Volume flow, free-blowing	25 m <sup>3</sup> /h
Width of installation cut-outs	92 mm	With filter	Yes

## Classifications

ETIM 6.0	EC000320	eClass 6.2	27-18-07-16
eClass 9.1	27-18-07-16		

## Approvals

Approvals



ROHS Conform

## Downloads


Approval/Certificate/Document of Conformity	<a href="#">EU Declaration of Conformity</a>
Engineering Data	<a href="#">STEP</a>

**FF 11 54/230V BK**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com

**Drawings**

**Graph**

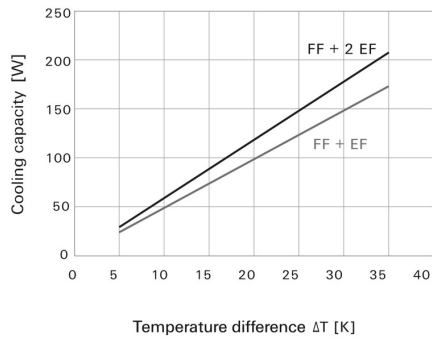

**Graph**

