

FF 22 54/230V BK**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com



The filter fans combine a safe and profitable cabinet cooling due to their low energy consumption by maximum air flow. The fluted filter mat of the IP 55 version extends the service life by up to 300% in comparison to conventional filter mats.

General ordering data

Type	FF 22 54/230V BK
Order No.	2556630000
Version	Filter fan, 230 V, 230 V, IP54, black
GTIN (EAN)	4050118567250
Qty.	1 pc(s).

FF 22 54/230V BK

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

Technical data

Dimensions and weights

Width	145 mm	Width (inches)	5.709 inch
Height	145 mm	Height (inches)	5.709 inch
Depth	70 mm	Depth (inches)	2.756 inch
Net weight	700 g		

General data

EMC version	No	Filter class	G 3
Height of installation cut-outs	125 mm	Mounting depth	70 mm
Mounting height	5 mm	Noise emission	44 dB (A)
Rated AC voltage	230 V AC	Supply voltage, max	230 V
Supply voltage, min.	230 V	Type of connection	Terminal strip
Type of mounting	Snap-on	Volume flow, free-blowing	61 m ³ /h
Width of installation cut-outs	125 mm	With filter	Yes

Classifications

ETIM 6.0	EC000320	eClass 6.2	27-18-07-16
eClass 9.1	27-18-07-16		

Approvals

Approvals



ROHS

Conform

Downloads

Approval/Certificate/Document of Conformity	EU Declaration of Conformity
Engineering Data	STEP


Data sheet

FF 22 54/230V BK

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Drawings

Graph

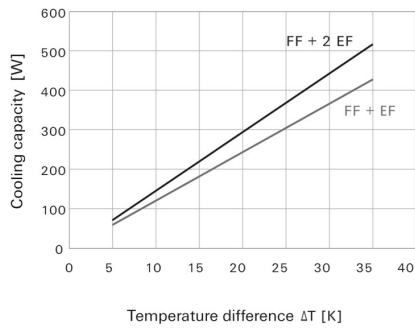

Graph

