

FF 42 55/230V GY**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

Similar to illustration

The filter fans combine a safe and profitable cabinet cooling due to their low energy consumption by maximum air flow. The fluted filter mat of the IP 55 version extends the service life by up to 300% in comparison to conventional filter mats.

General ordering data

Type	FF 42 55/230V GY
Order No.	2556770000
Version	Filter fan, 230 V, 230 V, IP55, grey
GTIN (EAN)	4050118567397
Qty.	1 pc(s).

FF 42 55/230V GY

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

Technical data

Dimensions and weights

Width	252 mm	Width (inches)	9.921 inch
Height	252 mm	Height (inches)	9.921 inch
Depth	103 mm	Depth (inches)	4.055 inch
Net weight	1,180 g		

General data

EMC version	No	Filter class	G 4
Height of installation cut-outs	223 mm	Mounting depth	97 mm
Mounting height	6 mm	Noise emission	40 dB (A)
Rated AC voltage	230 V AC	Supply voltage, max	230 V
Supply voltage, min.	230 V	Type of connection	Spring contact
Type of mounting	Snap-on	Volume flow, free-blowing	145 m ³ /h
Width of installation cut-outs	223 mm	With filter	Yes

Classifications

ETIM 6.0	EC000320	eClass 6.2	27-18-07-16
eClass 9.1	27-18-07-16		

Approvals

Approvals



ROHS Conform

Downloads


Approval/Certificate/Document of Conformity	EU Declaration of Conformity
Engineering Data	STEP

FF 42 55/230V GY

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Drawings

Graph

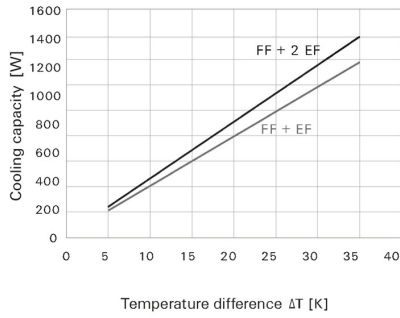

Graph

