

**FF 43 55/230V GY**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 16  
D-32758 Detmold  
Germany  
Fon: +49 5231 14-0  
Fax: +49 5231 14-292083  
www.weidmueller.com

**Similar to illustration**

The filter fans combine a safe and profitable cabinet cooling due to their low energy consumption by maximum air flow. The fluted filter mat of the IP 55 version extends the service life by up to 300% in comparison to conventional filter mats.

**General ordering data**

Type	FF 43 55/230V GY
Order No.	<a href="#">2556840000</a>
Version	Filter fan, 230 V, 230 V, IP55, grey
GTIN (EAN)	4050118567465
Qty.	1 pc(s).

## FF 43 55/230V GY

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

## Technical data

## Dimensions and weights

Width	252 mm	Width (inches)	9.921 inch
Height	252 mm	Height (inches)	9.921 inch
Depth	119 mm	Depth (inches)	4.685 inch
Net weight	1,670 g		

## General data

EMC version	No	Filter class	G 4
Height of installation cut-outs	223 mm	Mounting depth	113 mm
Mounting height	6 mm	Noise emission	42 dB (A)
Rated AC voltage	230 V AC	Supply voltage, max	230 V
Supply voltage, min.	230 V	Type of connection	Spring contact
Type of mounting	Snap-on	Volume flow, free-blowing	233 m <sup>3</sup> /h
Width of installation cut-outs	223 mm	With filter	Yes

## Classifications

ETIM 6.0	EC000320	eClass 6.2	27-18-07-16
eClass 9.1	27-18-07-16		

## Approvals

Approvals



ROHS

Conform

## Downloads


Approval/Certificate/Document of Conformity	<a href="#">EU Declaration of Conformity</a>
Engineering Data	<a href="#">STEP</a>

**FF 43 55/230V GY**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com

**Drawings**

**Graph**

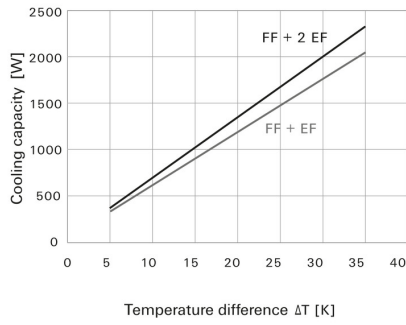

**Graph**

