

**FF 65 55/230V BK****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

**Similar to illustration**

The filter fans combine a safe and profitable cabinet cooling due to their low energy consumption by maximum air flow. The fluted filter mat of the IP 55 version extends the service life by up to 300% in comparison to conventional filter mats.

**General ordering data**

|            |                                       |
|------------|---------------------------------------|
| Type       | FF 65 55/230V BK                      |
| Order No.  | <a href="#">255690000</a>             |
| Version    | Filter fan, 230 V, 230 V, IP55, black |
| GTIN (EAN) | 4050118567526                         |
| Qty.       | 1 pc(s).                              |

**FF 65 55/230V BK****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

**Technical data****Dimensions and weights**

|            |         |                 |             |
|------------|---------|-----------------|-------------|
| Width      | 320 mm  | Width (inches)  | 12.598 inch |
| Height     | 320 mm  | Height (inches) | 12.598 inch |
| Depth      | 157 mm  | Depth (inches)  | 6.181 inch  |
| Net weight | 3,200 g |                 |             |

**General data**

|                                 |          |                           |                       |
|---------------------------------|----------|---------------------------|-----------------------|
| EMC version                     | No       | Filter class              | G 4                   |
| Height of installation cut-outs | 291 mm   | Mounting depth            | 140 mm                |
| Mounting height                 | 7 mm     | Noise emission            | 54 dB (A)             |
| Rated AC voltage                | 230 V AC | Supply voltage, max       | 230 V                 |
| Supply voltage, min.            | 230 V    | Type of connection        | Spring contact        |
| Type of mounting                | Snap-on  | Volume flow, free-blowing | 505 m <sup>3</sup> /h |
| Width of installation cut-outs  | 291 mm   | With filter               | Yes                   |

**Classifications**

|            |             |            |             |
|------------|-------------|------------|-------------|
| ETIM 6.0   | EC000320    | eClass 6.2 | 27-18-07-16 |
| eClass 9.1 | 27-18-07-16 |            |             |

**Approvals**

Approvals



ROHS

Conform

**Downloads**


|   |  |
|---|--|
| Approval/Certificate/Document of Conformity | <a href="#">EU Declaration of Conformity</a> |
| Engineering Data                            | <a href="#">STEP</a>                         |

## FF 65 55/230V BK

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 16  
D-32758 Detmold  
Germany  
Fon: +49 5231 14-0  
Fax: +49 5231 14-292083  
www.weidmueller.com

# Drawings

### Graph

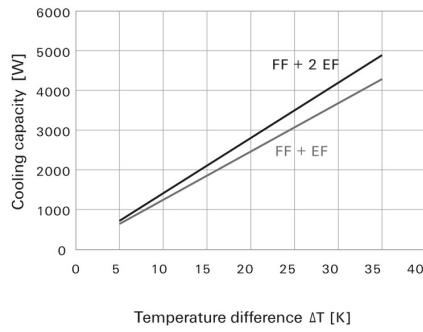

### Graph

