

RFF 610 54/230V GY**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

Similar to illustration

The filter fans combine a safe and profitable cabinet cooling due to their low energy consumption by maximum air flow. The fluted filter mat of the IP 55 version extends the service life by up to 300% in comparison to conventional filter mats.

General ordering data

Type	RFF 610 54/230V GY
Order No.	2557810000
Version	Filter fan, 230 V, 230 V, IP54, grey
GTIN (EAN)	4050118568455
Qty.	1 pc(s).

RFF 610 54/230V GY**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

Technical data**Dimensions and weights**

Width	470 mm	Width (inches)	18.504 inch
Height	470 mm	Height (inches)	18.504 inch
Depth	470 mm	Depth (inches)	18.504 inch
Net weight	4,300 g		

General data

EMC version	No	Filter class	G 3
Height of installation cut-outs	291 mm	Mounting depth	57 mm
Mounting height	95 mm	Noise emission	77 dB (A)
Rated AC voltage	230 V AC	Supply voltage, max	230 V
Supply voltage, min.	230 V	Type of connection	Terminal strip
Type of mounting	Snap-on	Volume flow, free-blowing	750 m ³ /h
Width of installation cut-outs	291 mm	With filter	Yes

Classifications

ETIM 6.0	EC000320	eClass 6.2	27-18-07-16
eClass 9.1	27-18-07-16		

Approvals

Approvals



ROHS Conform

Downloads


Approval/Certificate/Document of Conformity	EU Declaration of Conformity
Engineering Data	STEP

RFF 610 54/230V GY

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Drawings

Graph

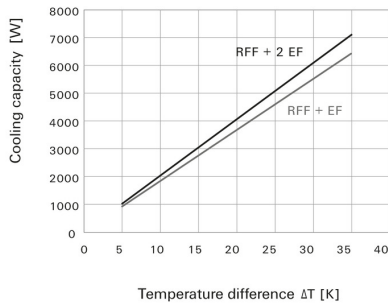

Graph

