

**FF 32 54/230V GY****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com



The filter fans combine a safe and profitable cabinet cooling due to their low energy consumption by maximum air flow. The fluted filter mat of the IP 55 version extends the service life by up to 300% in comparison to conventional filter mats.

**General ordering data**

Type	FF 32 54/230V GY
Order No.	<a href="#">2556680000</a>
Version	Filter fan, 230 V, 230 V, IP54, grey
GTIN (EAN)	4050118567304
Qty.	1 pc(s).

## FF 32 54/230V GY

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

## Technical data

## Dimensions and weights

Width	202 mm	Width (inches)	7.953 inch
Height	202 mm	Height (inches)	7.953 inch
Depth	93 mm	Depth (inches)	3.661 inch
Net weight	870 g		

## General data

EMC version	No	Filter class	G 3
Height of installation cut-outs	177 mm	Mounting depth	87 mm
Mounting height	6 mm	Noise emission	40 dB (A)
Rated AC voltage	230 V AC	Supply voltage, max	230 V
Supply voltage, min.	230 V	Type of connection	Terminal strip
Type of mounting	Snap-on	Volume flow, free-blowing	110 m <sup>3</sup> /h
Width of installation cut-outs	177 mm	With filter	Yes

## Classifications

ETIM 6.0	EC000320	eClass 6.2	27-18-07-16
eClass 9.1	27-18-07-16		

## Approvals

Approvals



ROHS Conform

## Downloads

Approval/Certificate/Document of Conformity	<a href="#">EU Declaration of Conformity</a>
Engineering Data	<a href="#">STEP</a>


**Data sheet**

**FF 32 54/230V GY**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com

**Drawings**

**Graph**

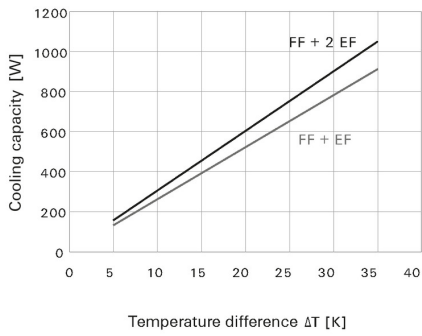

**Graph**

