

FF 67 55/230V BK**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

Similar to illustration

The filter fans combine a safe and profitable cabinet cooling due to their low energy consumption by maximum air flow. The fluted filter mat of the IP 55 version extends the service life by up to 300% in comparison to conventional filter mats.

General ordering data

Type	FF 67 55/230V BK
Order No.	2556980000
Version	Filter fan, 230 V, 230 V, IP55, black
GTIN (EAN)	4050118567601
Qty.	1 pc(s).

FF 67 55/230V BK**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

Technical data**Dimensions and weights**

Width	320 mm	Width (inches)	12.598 inch
Height	320 mm	Height (inches)	12.598 inch
Depth	157 mm	Depth (inches)	6.181 inch
Net weight	3,700 g		

General data

EMC version	No	Filter class	G 4
Height of installation cut-outs	291 mm	Mounting depth	150 mm
Mounting height	7 mm	Noise emission	66 dB (A)
Rated AC voltage	230 V AC	Supply voltage, max	230 V
Supply voltage, min.	230 V	Type of connection	Spring contact
Type of mounting	Snap-on	Volume flow, free-blowing	925 m ³ /h
Width of installation cut-outs	291 mm	With filter	Yes

Classifications

ETIM 6.0	EC000320	eClass 6.2	27-18-07-16
eClass 9.1	27-18-07-16		

Approvals

Approvals



ROHS Conform

Downloads

Approval/Certificate/Document of Conformity	EU Declaration of Conformity
Engineering Data	STEP


Data sheet

FF 67 55/230V BK

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Drawings

Graph

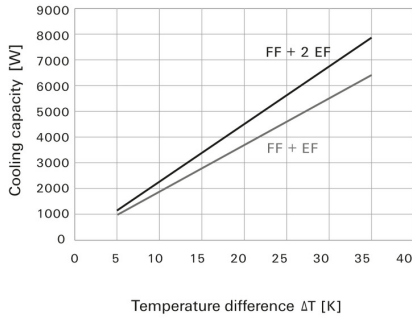

Graph

