


Data Sheet

Emergency switch

Version 07/19

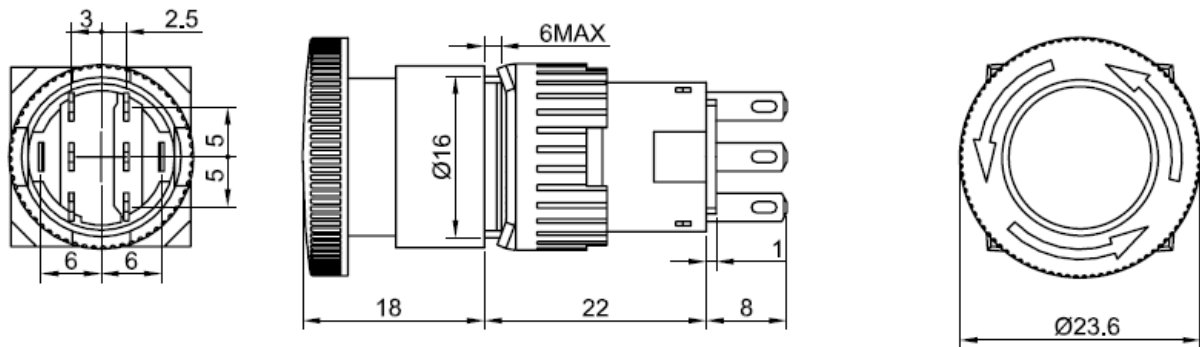

6MAX: means the panel thickness, the max thickness for the panel no more than 6mm.

Specification

Mounting diameter	16mm
Operation type	Push on turn reset
Contact structure	1NO1NC
Switch rating	250VAC/3A
Terminal	Soldering Pins
Body material	PC
Operating and storage temperature	-25 to +55 °C
Operating and storage humidity	45 to 85 % RH
Base material	PBT
IP rating	IP40