


## Data Sheet

### Emergency switch

Version 07/19

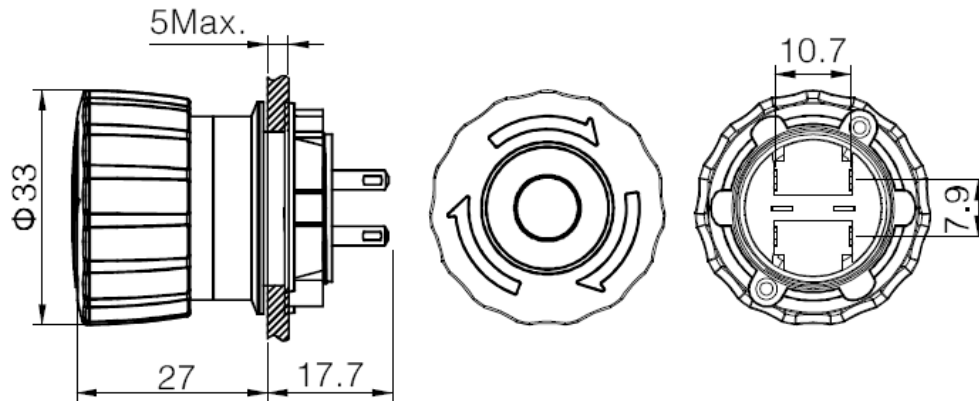

5MAX: means the panel thickness, the max thickness for the panel no more than 5mm.

### Specification

|                                         |                    |
|-----------------------------------------|--------------------|
| Mounting diameter .....                 | 22mm               |
| Operation type .....                    | Push on turn reset |
| Contact structure .....                 | 1NC / 2NC / 1NO1NC |
| Switch rating .....                     | 250VAC/3A          |
| Terminal .....                          | Soldering Pins     |
| Body material .....                     | PA                 |
| Operating and storage temperature ..... | -25 to +55 °C      |
| Operating and storage humidity .....    | 45 to 85 % RH      |
| Base material .....                     | PA                 |
| IP rating .....                         | IP65               |

| Item no. | Contact structure |
|----------|-------------------|
| 1873612  | 1NC               |
| 1873613  | 2NC               |
| 1873614  | 1NO1NC            |