


# Data Sheet

## Push button switch

## Version 08/21

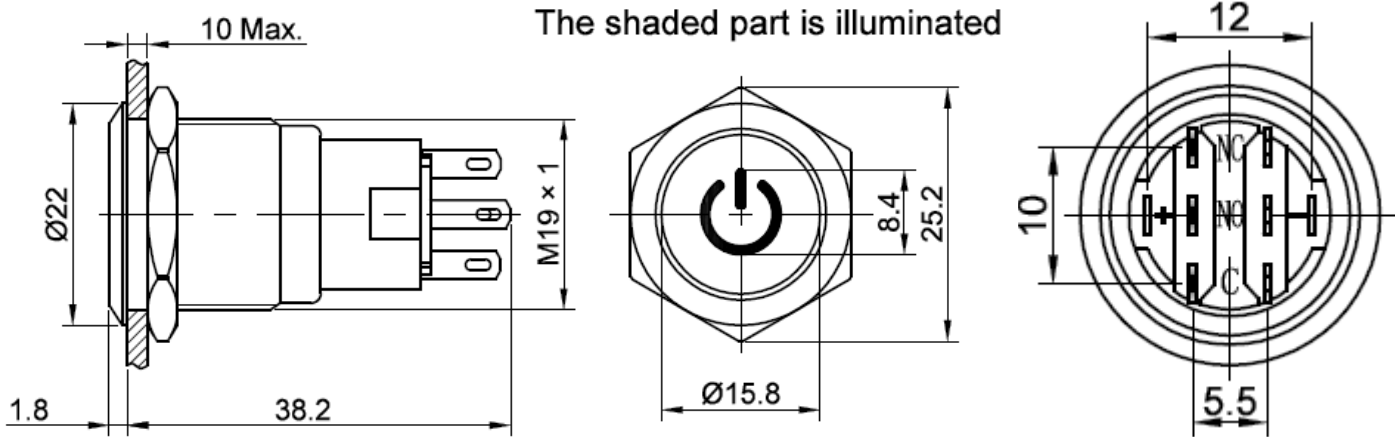

10 MAX: means the panel thickness, the max thickness for the panel no more than 10mm.

## Specification

Mounting diameter .....	19 mm
Head shape .....	Flat round head
Operation type .....	Momentary / Latching
Contact structure .....	1NO1NC
Switch rating .....	250VAC/3A
Illumination type .....	Power symbol
Terminal .....	Soldering Pins
Body material .....	Stainless steel
Operating and storage temperature .....	-25 to +55 °C
Operating and storage humidity .....	45 to 85 % RH
Base material .....	PBT
IP rating .....	IP65

## Data Sheet

---

Item no.	Operation type	LED color	LED voltage
1873619	momentary	Red	12 V
1873620	momentary	Green	12 V
1873621	momentary	Blue	12 V
1873622	momentary	White	12 V
1873623	latching	Red	12 V
1873624	latching	Green	12 V
1873625	latching	Blue	12 V
1873626	latching	White	12 V