


Data Sheet

Push button switch

Version 08/21

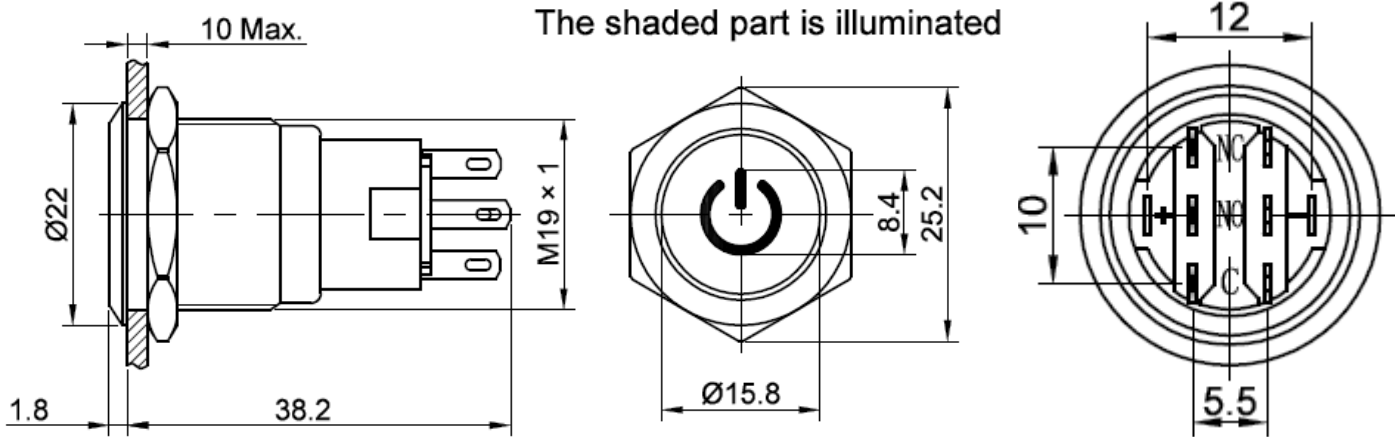

10 MAX: means the panel thickness, the max thickness for the panel no more than 10mm.

Specification

Mounting diameter	19 mm
Head shape	Flat round head
Operation type	Momentary / Latching
Contact structure	1NO1NC
Switch rating	250VAC/3A
Illumination type	Power symbol
Terminal	Soldering Pins
Body material	Stainless steel
Operating and storage temperature	-25 to +55 °C
Operating and storage humidity	45 to 85 % RH
Base material	PBT
IP rating	IP65

Data Sheet

Item no.	Operation type	LED color	LED voltage
1873619	momentary	Red	12 V
1873620	momentary	Green	12 V
1873621	momentary	Blue	12 V
1873622	momentary	White	12 V
1873623	latching	Red	12 V
1873624	latching	Green	12 V
1873625	latching	Blue	12 V
1873626	latching	White	12 V