


## Data Sheet

### Push button switch

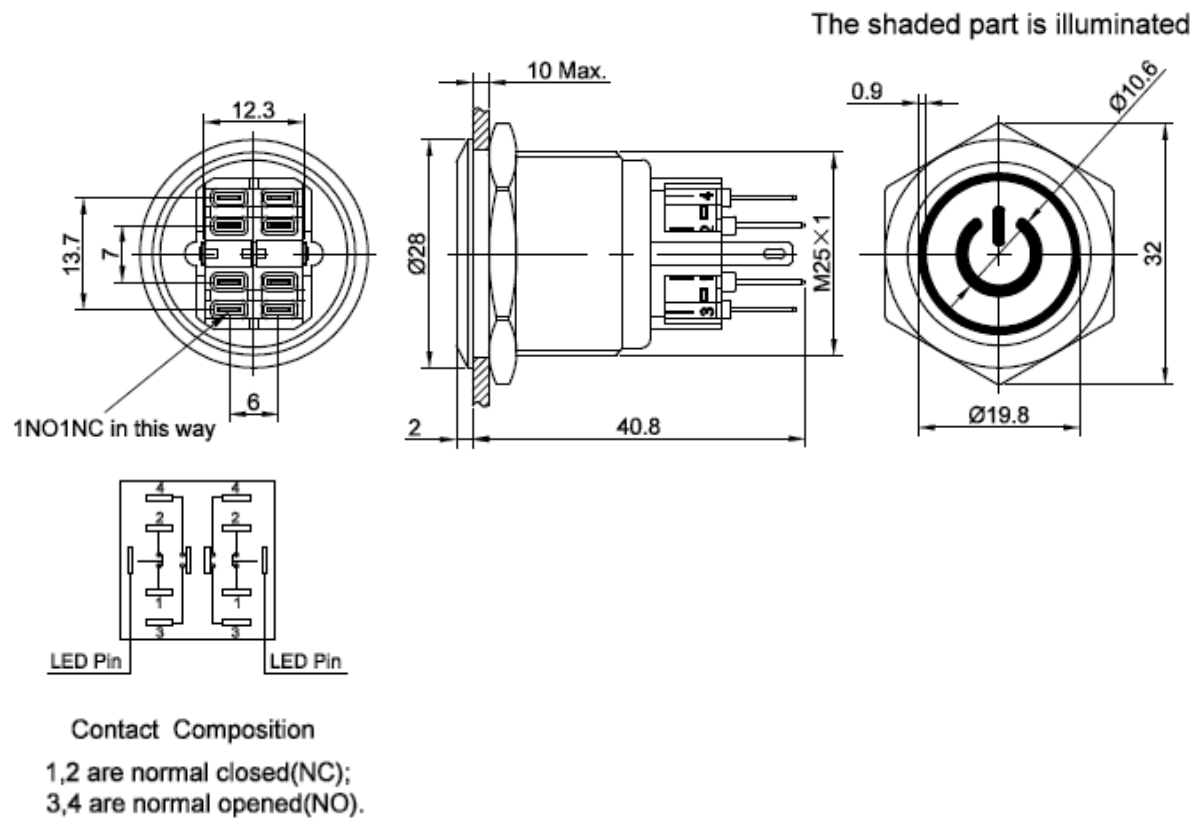

10 MAX: means the panel thickness, the max thickness for the panel no more than 10mm.

Item no.	Operation type	LED color	LED voltage
1873643	momentary	Red	12 V
1873644	momentary	Green	12 V
1873645	momentary	Blue	12 V
1873646	momentary	White	12 V
1873647	latching	Red	12 V
1873648	latching	Green	12 V
1873649	latching	Blue	12 V
1873650	latching	White	12 V

## Data Sheet

---

### Specification

Mounting diameter .....	25mm
Head shape .....	Flat round head
Operation type .....	Momentary / Latching
Contact structure .....	1NO1NC
Switch rating .....	250VAC/3A
Illumination type .....	Ring and Power symbol
Terminal .....	Soldering Pins
Body material .....	Stainless steel
Operating and storage temperature .....	-25 to +55 °C
Operating and storage humidity .....	45 to 85 % RH
Base material .....	PC
IP rating .....	IP65