


# Data Sheet

## Push button switch

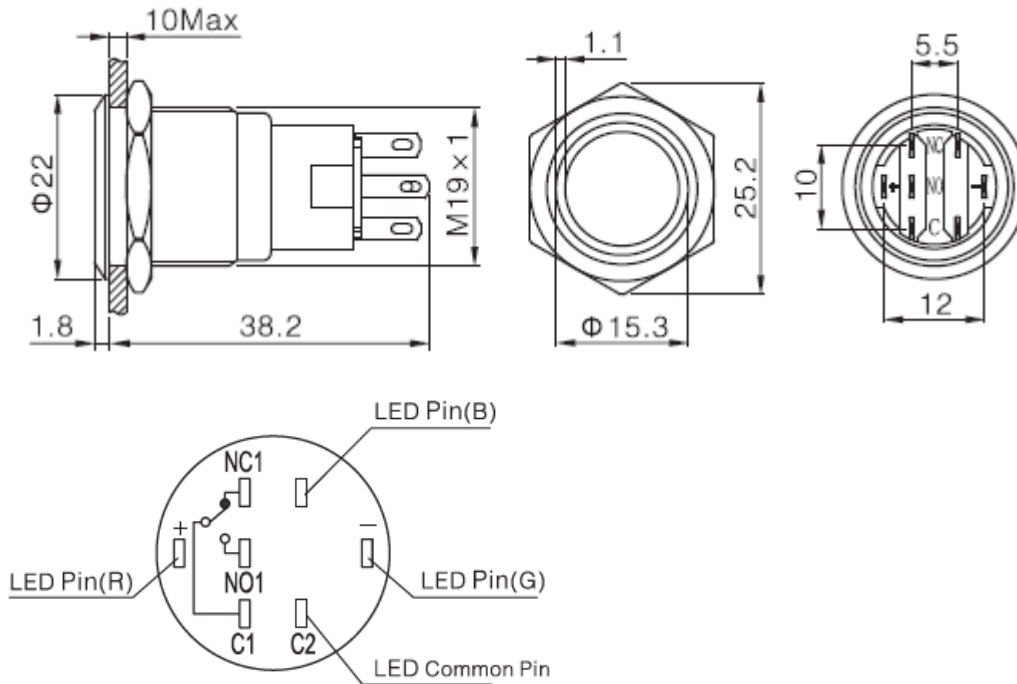

10 MAX: means the panel thickness, the max thickness for the panel no more than 10mm.

### Technical data

Mounting diameter .....	19mm
Head shape .....	Flat round head
Operation type .....	Momentary / Latching
Contact structure .....	1NO1NC
Switch rating .....	250VAC/3A
Illumination type .....	Ring
Terminal .....	Soldering Pins
Body material .....	Stainless steel
Operating and storage temperature .....	-25 to +55 °C
Operating and storage humidity .....	45 to 85 % RH
Base material .....	PBT
IP rating .....	IP65

## Data Sheet

---

Item no.	Operation type	Common Pin	LED color	LED voltage
1873655	momentary	Common cathode	RGB	12 V
1873656	momentary	Common anode	RGB	12 V
1873657	latching	Common cathode	RGB	12 V
1873658	latching	Common anode	RGB	12 V