


NO MERCURY ADDED	
Description	: Mercury & Cadmium Free Lithium / Iron Disulfide battery AA Size
Chemical System	: Lithium / Iron Disulfide (Li/FeS ₂)
Nominal Voltage	: 1.5 Volts
Nominal Dimensions	: Ø14.5 mm x 50.5 mm
Terminals	: Protruded positive(+) and flat negative(-) contacts
Jacket	: Foil jacket
Applications	: All electronic devices, e.g. Digital cameras, photoflash, toys, shavers, universal handheld GPS devices
Shelf life	: 10 years at 21°C (80% rated capacity)
Average Weight	: 14.5g

Cross References:


GP	JIS	IEC	Energizer	Duracell
15LF	FR6	FR6	L91	LF1500

Model No.: GP15LF

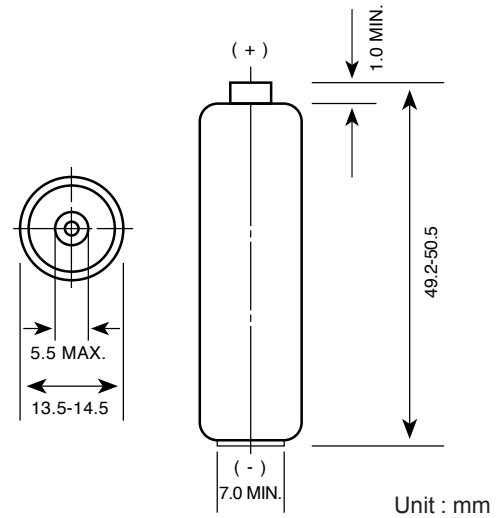


Constant Current Performance (21°C)

Typical Characteristics to 1.0 V

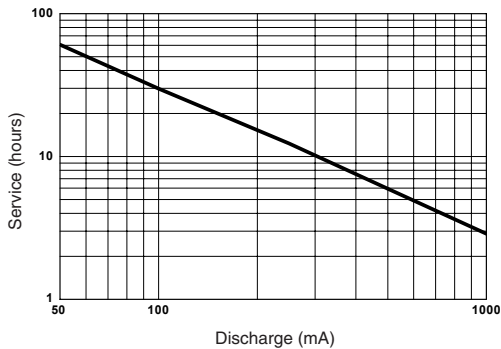

Constant Power Performance (21°C)


Typical Characteristics to 1.0 V

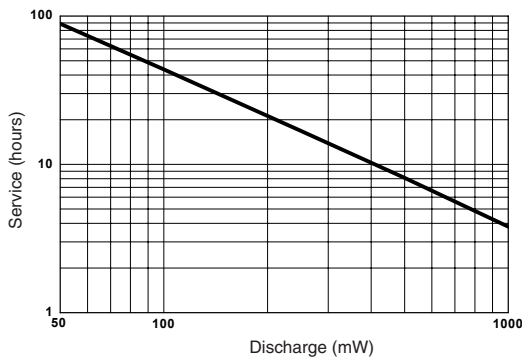


The information (subject to change without prior notice) contained in this document is for reference only and should not be used as a basis for product guarantee or warranty. For applications other than those described here, please consult your nearest GP Sales and Marketing Office or Distributors.

www.gpbatteries.com

Application Tests(23±2°C)

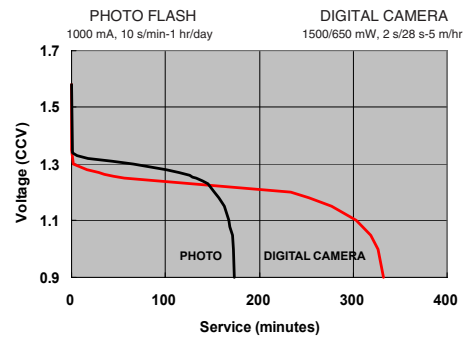

Application Tests(23±2°C)

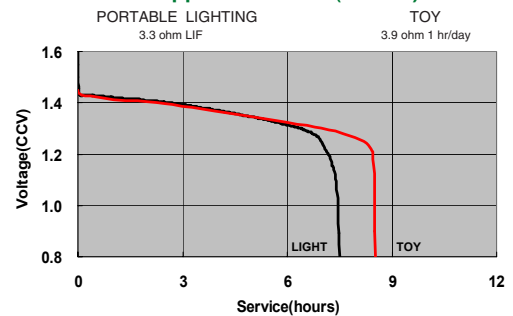

Application Tests(23±2°C)

