

Product sheet

Basic Information

Order Number
Type
Common Number


850EMIDS30WZS2731
ZS2731
ZS2731



8592920039984

Measuring Unit
Packaging
Net Weight [kg]
Dimensions [mm]

Pcs
1 / - / 6
1,075
225 × 75 × 200

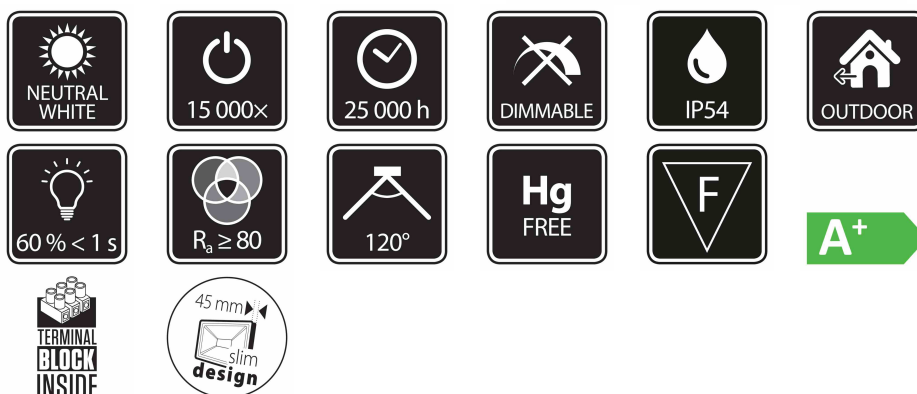

Technical Description

source of light
power
replacement of incandescent bulb
IP rating
luminous flux
color temperature
light color
color rendering index (CRI)

LED
30 W
260 W
IP54
2 400 lm
4 000 K
neutral white
Ra > 80

Product sheet

beam angle	120°
PIR sensor	yes
detection range of PIR Sensor	10 m
dimensions	196 × 61 × 207 mm
colour	grey
voltage	220–240 V~
current	140 mA
frequency	50/60 Hz
lifetime	25 000 hours
mechanical impact protection (IK)	IK08
warranty period	2 years
material of the diffuser	glass
body material	aluminum
working temperature range	-20 °C to +40 °C
line	IDEO
packaging	1 pc, box