

# LED floodlight PROFI 50W PIR, neutral white

## Product sheet

### Basic Information

Order Number  
Type  
Common Number

**850EMPRS40WZS2740**  
**ZS2740**  
**ZS2740**




8592920026373



Measuring Unit  
Packaging  
Net Weight [kg]  
Dimensions [mm]

Pcs  
1 / - / 4  
2,549  
325 × 145 × 295

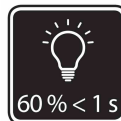

### Technical Description

source of light	LED
power	50 W
replacement of incandescent bulb	550 W
IP rating	IP44
luminous flux	5 000 lm
color temperature	4 000 K
light color	neutral white
color rendering index (CRI)	Ra > 70

## Product sheet

beam angle	120°
PIR sensor	yes
detection range of PIR Sensor	12 m
dimensions	284 × 300 × 138 mm
colour	grey
voltage	100–240 V
current	220 mA
frequency	50/60 Hz
lifetime	40 000 hours
mechanical impact protection (IK)	IK08
warranty period	3 years
material of the diffuser	glass
body material	aluminum
working temperature range	-20 °C to +40 °C
line	PROFI
packaging	1 pc, box