

SPECIFICATION:

Operating Voltage (Max.):	30 V
Operating Current (Nom.):	1 A
Operating Temperature:	-40°C to 105°C
Insulation Resistance (Min.):	1000 MΩ
Contact Resistance (Max.):	30 mΩ
Dielectric Strength:	100 Vac
Insertion Force (Max.):	29.4 N
Extraction Force:	4.9 N



MATERIAL:


Material (Terminal):	copper alloy, tin plated
Material (Housing):	copper alloy
Flammability Class:	UL 94 V-0
Material (Insulation):	LCP
Material (Contact Area):	copper alloy, gold plated

HANDLING:

Packaging:	tray
------------	------

TOLERANCE:

.X:	± 0.25
.XX:	± 0.20

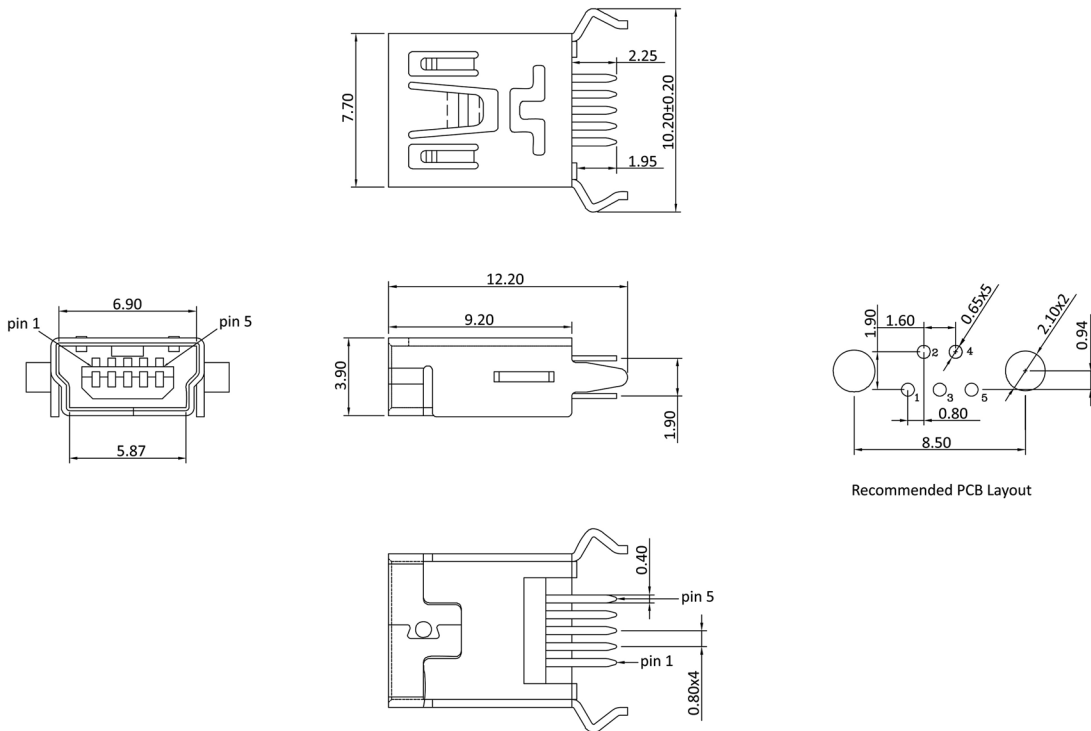

Order Information

Identifier:

MUB1B5HN

Socket 5 poles vertical