

## Contact Strips Pitch 2.54 mm, straight

Machine Pins, single row



### SPECIFICATION:

Operating Voltage (Max.):	60 V
Operating Current (Nom.):	3 A
Operating Temperature:	-55°C to 125°C
Insulation Resistance (Min.):	1000 MΩ
Contact Resistance (Max.):	4 mΩ

### MATERIAL:




Material (Terminal):	brass, machined pins
Material (Housing):	polyester Valox
Flammability Class:	UL 94 V-0
Material (Contact Area):	beryllium copper, gold plated

### HANDLING:

Processing:	wave soldering
Packaging:	bulk

### TOLERANCE:

.X:	± 0.50
.XX:	± 0.30

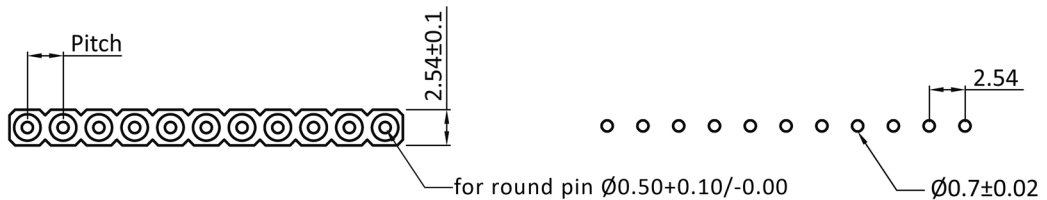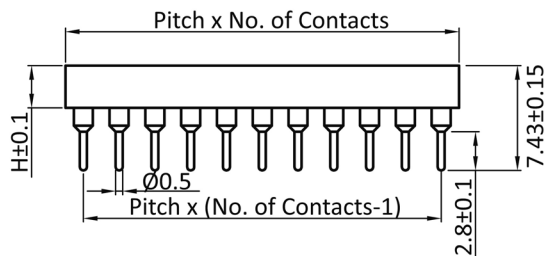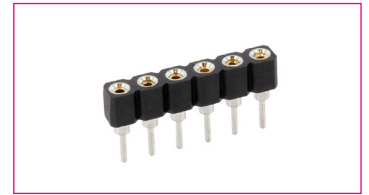

### Order Information

Identifier:	No. of Contacts:	Pitch:	Contact Plating:	Insulator Height:
SCS	#	#	#	3
Socket connector strip single row, gedrehte Kontakte	1: 1 x 1 2: 1 x 2 3: 1 x 3 : 64: 1 x 64	E: Pitch 1.778 mm A: Pitch 2.54 mm * B: Pitch 5.08 mm C: Pitch 7.62 mm	A: contact 200 μ" tin plated / spring gold flashed * B: contact 200 μ" tin plated / spring 10 μ" gold C: contact 200 μ" tin plated / spring 30 μ" gold	height 3.0 mm

\* = Standard