

Pin Headers Pitch 2.54 mm, angled

Double row Nylon



SPECIFICATION:

Operating Current (Nom.): 3 A
 Operating Temperature: -40°C to 105°C
 Insulation Resistance (Min.): 1000 MΩ
 Contact Resistance (Max.): 20 mΩ
 Dielectric Strength: 1,000 Vac

MATERIAL:



Material (Terminal): copper alloy
 Material (Insulation): nylon 6T
 Flammability Class: UL 94 V-0
 Material (Contact Area): copper alloy, gold plated

HANDLING:

Processing: wave soldering
 Packaging: bulk

TOLERANCE:

.X: ± 0.25
 .XX: ± 0.20

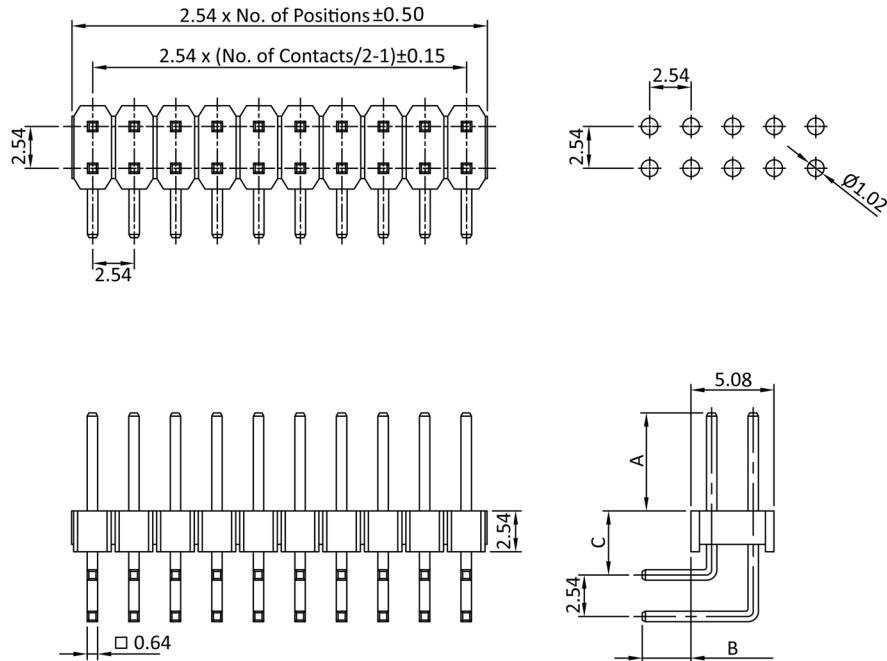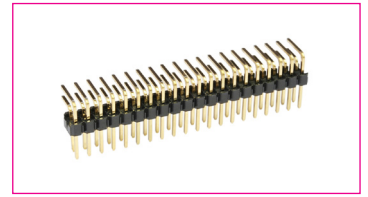

Order Information

Identifier:	No. of Contacts:	Contact Plating:	Length:
SL25WD	#	#	#
Pin header pitch 2.54 mm double row angled	4: 2 x 2 6: 2 x 3 8: 2 x 4 :	G: gold plated * A: 5 μ" gold B: 10 μ" gold D: 30 μ" gold S: selective gold plated	A: A=6.0 B=3.0 C=3.9 * X: Special dimensions also available

* = Standard