

**Board-to-Wire Connectors
Pitch 3.96 mm Series CGM**

Housings CGM series single row



SPECIFICATION:




Operating Voltage (Max.): 250 V
 Operating Current (Nom.): 5 A
 Operating Temperature: -25°C to 85°C
 Insulation Resistance (Min.): 1000 MΩ
 Contact Resistance (Max.): 10 mΩ
 Dielectric Strength: 1,500 Vac

MATERIAL:

Material (Housing): nylon 66
 Flammability Class: UL 94 V-2

HANDLING:

Packaging: bulk

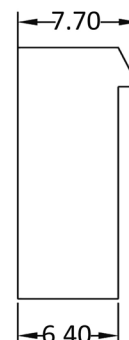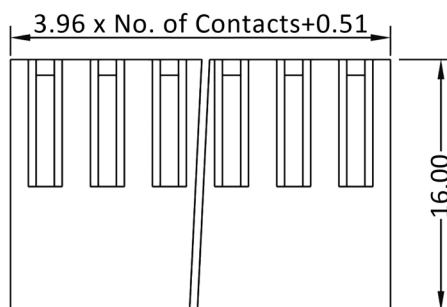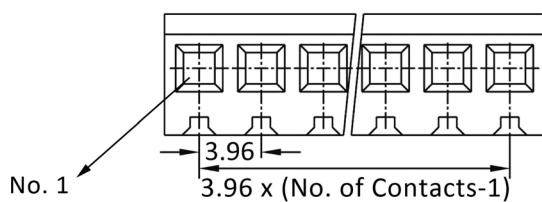

Order Information

Identifier:

CGM

Housing series CGM pitch 3.96 mm single row

No. of Contacts:

#

2: 1 x 2

3: 1 x 3

4: 1 x 4

:

20: 1 x 20