

**Board-to-Wire Connectors
Pitch 2.5 mm Series H33H**

**Wafers for Housing Series H33H single
row, angled**



**RoHS
COMPLIANT**

SPECIFICATION:

Current rating: 3 A
Voltage rating: 250 V
Insulation resistance: 1000 MΩ min.
Contact resistance: 20 mΩ max.
Dielectric voltage: 800 V AC
Operation temperature: -40 °C to +85 °C

MATERIAL:

Housing: Nylon 66 white UL94V-0
Contacts: Brass

FINISH:



 


Contacts: Tin plated

HANDLING:

Packing: Bulk

TOLERANCE:

.X ± 0.25
.XX ± 0.20

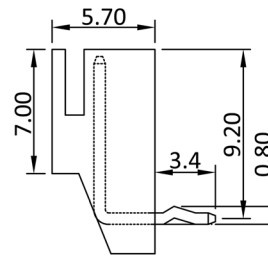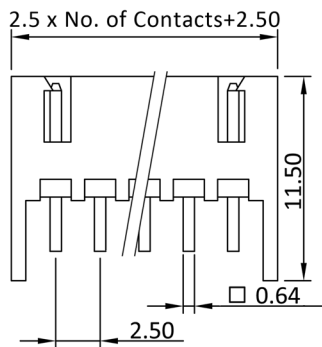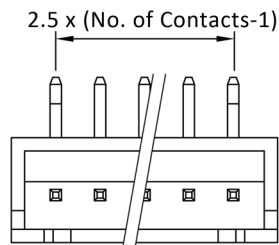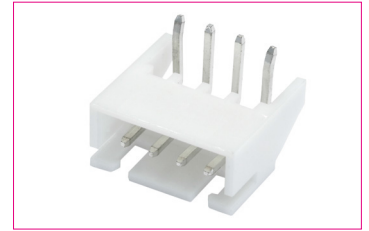

Order-Information

Identifier:

W33R

Wafer Series H33H Pitch 2.5 mm single row angled

No. of contacts:

#

2: 1 x 2

3: 1 x 3

4: 1 x 4

:

20: 1 x 20