

SPECIFICATION:

Operating Voltage (Max.): 250 V
 Operating Current (Nom.): 5 A
 Operating Temperature: -25°C to 85°C
 Insulation Resistance (Min.): 1000 MΩ
 Contact Resistance (Max.): 10 mΩ
 Dielectric Strength: 1,500 Vac

MATERIAL:





Material (Housing): nylon 66
 Flammability Class: UL 94 V-0

HANDLING:

Packaging: bulk

TOLERANCE:

.X: ± 0.50
 .XX: ± 0.25

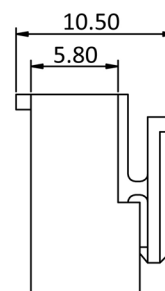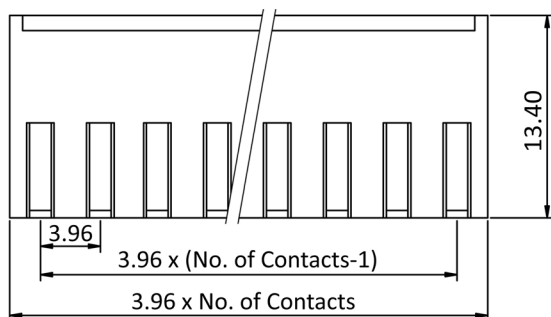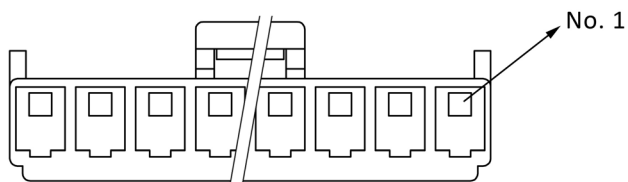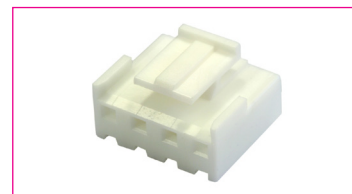

Order Information

Identifier:	No. of Contacts:	Pitch:
CVG	#	3
Housing series CVG pitch 3.96 mm single row	2: 1 x 2	Pitch 3.96 mm
	3: 1 x 3	
	4: 1 x 4	
	:	
	15: 1 x 15	