

# Pin Headers Pitch 2.54 mm, straight

Single row Nylon



### SPECIFICATION:

Operating Current (Nom.): 3 A  
 Operating Temperature: -40°C to 105°C  
 Insulation Resistance (Min.): 1000 MΩ  
 Contact Resistance (Max.): 20 mΩ  
 Dielectric Strength: 1,000 Vac

### MATERIAL:



Material (Terminal): copper alloy  
 Material (Insulation): nylon 6T  
 Flammability Class: UL 94 V-0  
 Material (Contact Area): copper alloy, gold plated

### HANDLING:

Processing: wave soldering  
 Packaging: bulk

### TOLERANCE:

.X: ± 0.35  
 .XX: ± 0.25

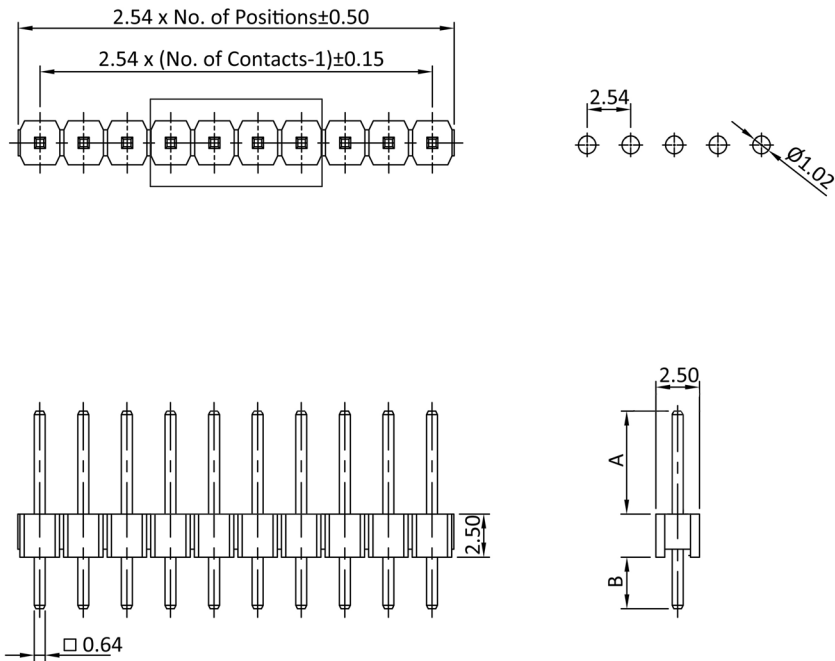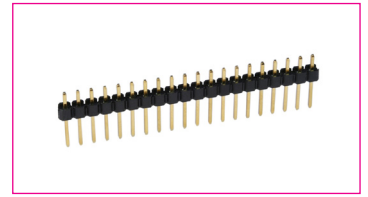

## Order Information

Identifier:	No. of Contacts:	Contact Plating:	Version:	Length:
SLSN	#	#	O	#
Pin header pitch 2.54 mm single row straight	2: 1 x 2 3: 1 x 3 4: 1 x 4 : 40: 1 x 40	G: gold plated * A: 5 μ" gold B: 10 μ" gold D: 30 μ" gold S: selective gold plated	w/o Cap	A: A=6.1 B=3.0 * B: A=7.1 B=3.0 * E: A=8.3 B=3.0 * F: A=12.3 B=3.0 * X: Special dimensions also available

\* = Standard