

Pin Headers Pitch 2.0 mm, straight

Single row Nylon, length 8.8 mm



SPECIFICATION:

Operating Current (Nom.): 2 A
 Operating Temperature: -40°C to 105°C
 Insulation Resistance (Min.): 1000 MΩ
 Contact Resistance (Max.): 20 mΩ
 Dielectric Strength: 500 Vac

MATERIAL:


Material (Terminal): copper alloy
 Material (Insulation): nylon 6T
 Flammability Class: UL 94 V-0
 Material (Contact Area): copper alloy, gold plated

HANDLING:



Packaging: bulk

TOLERANCE:

.X: ± 0.25
 .XX: ± 0.20

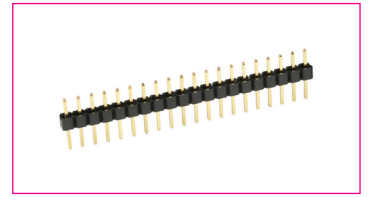

Recommended PCB Layout

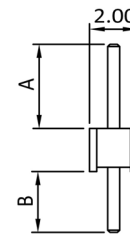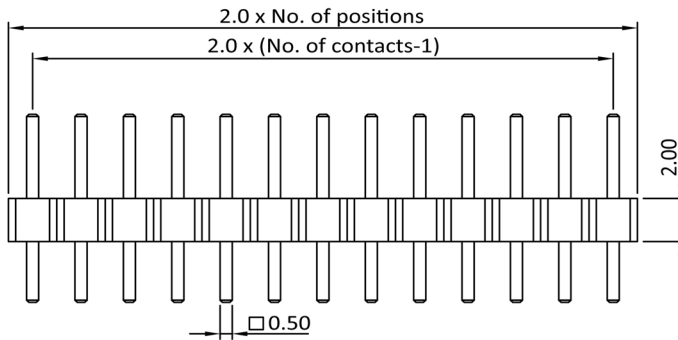

Order Information

| Identifier: | No. of Contacts: | Contact Plating: | Length: |
|---|-------------------|---------------------------------|---|
| SL20NS | # | # | # |
| Pin header pitch 2.0 mm single row straight | 2: 1 x 2 | G: gold plated * | A: A=4.0 B=2.8 * |
| | 3: 1 x 3 | A: 5 μ" gold | X: Special dimensions also available |
| | 4: 1 x 4 | B: 10 μ" gold | |
| | : | D: 30 μ" gold | |
| | 40: 1 x 40 | S: selective gold plated | |

* = Standard