

STABILA®



How true pro's measure

10

**YEAR
WARRANTY***

*In addition to the statutory claims,
refer to the explanations on the back page of the brochure

80 AS spirit level series:
Measurement accuracy that you can rely on –
quality made in Germany

STABILA 80 AS series: For all professionals who value accuracy

If you're looking for a tough and reliable spirit level with a slim profile, this model is just the ticket. The 80 AS series reinforced aluminium rectangular profile, together with STABILA installation technology, ensures long-lasting accuracy and a long service life. The vials and the measuring surfaces align perfectly with one another during the production process and are permanently connected. This is how STABILA ensures that the spirit level measures with absolute precision even after many years of use.

Do you need to frequently make markings or need magnets to align and adjust components? No problem – we can offer you the right spirit level for every task.

The choice is up to you!



Slim, stable and handy profile for any measuring task

The spirit level is especially suitable for use in the fields of gardening and landscaping work, reinforced concrete construction, carpentry as well as joinery and tiling.

» Type 80 AS, Type 80 AS-2

Type 80 AS

Type 80 AS-2

Type 80 ASM



- End caps with an anti-slip stopper – for a firm seat when marking
- 2 measuring surfaces – accurate measuring in all positions

Special feature:

Two vertical vials allow quick readings in any position.

Special feature:

Rare-earth magnet system – for extra-strong adhesion to metal objects.

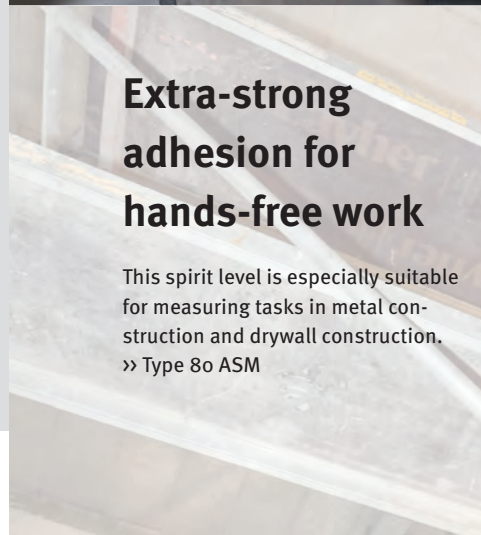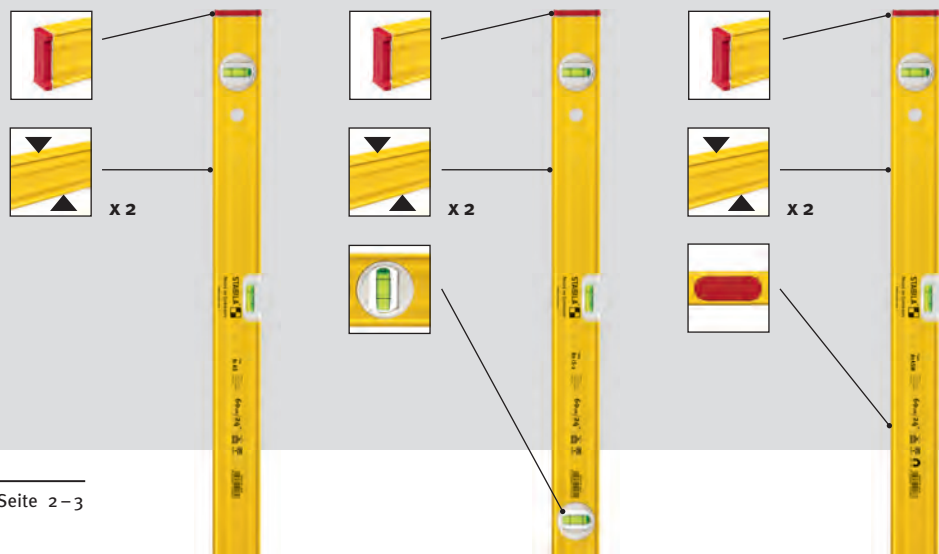

Extra-strong adhesion for hands-free work

This spirit level is especially suitable for measuring tasks in metal construction and drywall construction.


» Type 80 ASM



The key points at a glance:

Made in Germany

10 YEAR WARRANTY

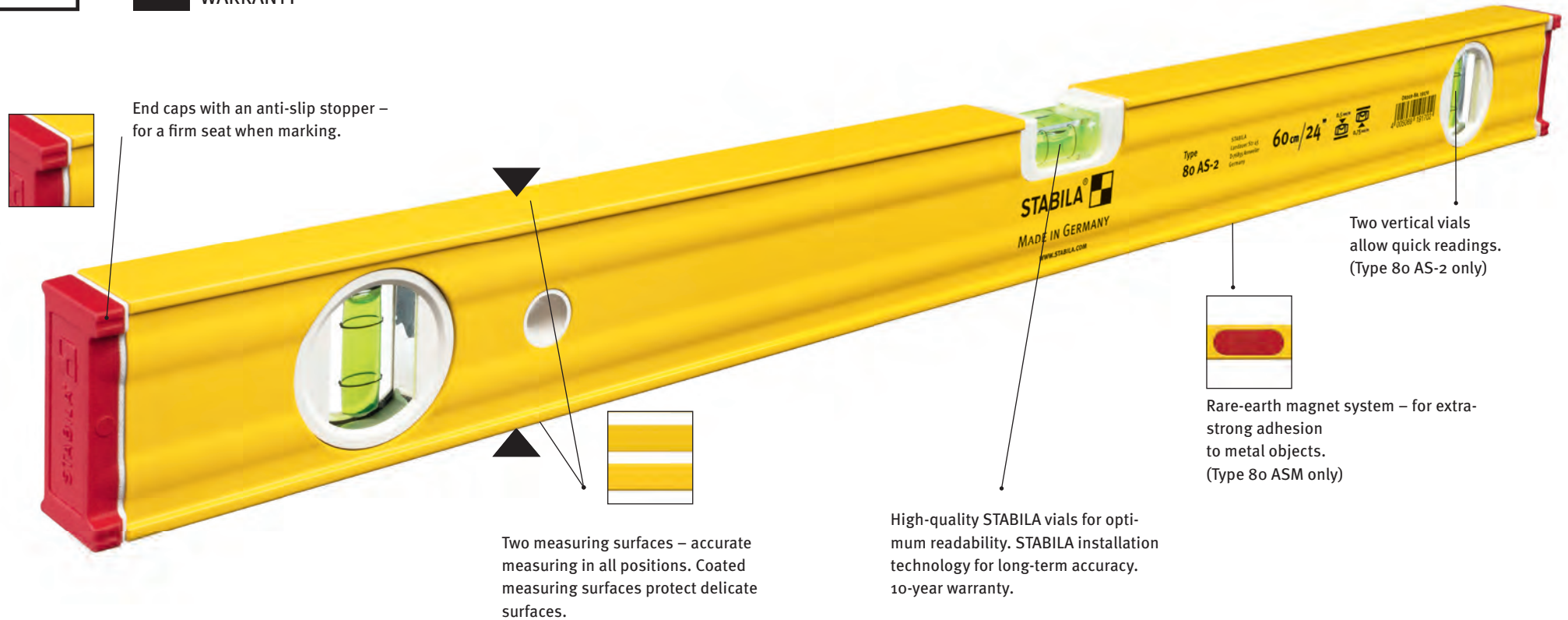

End caps with an anti-slip stopper – for a firm seat when marking.

Two measuring surfaces – accurate measuring in all positions. Coated measuring surfaces protect delicate surfaces.

High-quality STABILA vials for optimum readability. STABILA installation technology for long-term accuracy. 10-year warranty.

Two vertical vials allow quick readings. (Type 80 AS-2 only)

Rare-earth magnet system – for extra-strong adhesion to metal objects. (Type 80 ASM only)


Type 80 AS/80 AS-2/80 ASM

Integrated anti-slip stoppers allow for a firm hold when marking – the spirit level does not slip.



Type 80 AS-2

Two vertical vials allow quick readings in any position.

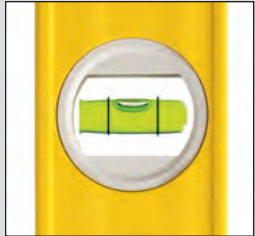

Type 80 ASM

Extra-strong rare-earth magnet system for adhesion to metal objects – leaves the hands free when aligning and adjusting pillars and supports (up to 5 x stronger than standard ferrite magnets).



Performance comparison and lengths:

Type	80 AS	80 AS-2	80 ASM
Accuracy in normal position	0.029° = 0.5 mm/m	0.029° = 0.5 mm/m	0.029° = 0.5 mm/m
Accuracy in reverse position	0.043° = 0.75 mm/m	0.043° = 0.75 mm/m	0.043° = 0.75 mm/m
Measuring surfaces	2 x	2 x	2 x
Vial type	1 x horizontal 1 x vertical	1 x horizontal 2 x vertical	1 x horizontal 1 x vertical
End caps	Anti-slip stopper	Anti-slip stopper	Anti-slip stopper
Special feature	-	Two vertical vials	Rare-earth magnet

Length	Art. No.	Art. No.	Art. No.
30 cm	19162	-	-
40 cm	19163	-	19177
50 cm	19164	-	-
60 cm	19165	19170	19178
80 cm	19166	19171	19179
90 cm	19167	19195	-
100 cm	19168	19172	19180
120 cm	19169	19173	19181
150 cm	-	19174	19182
180 cm	-	19175	19183
200 cm	-	19176	19184




STABILA Messgeräte
Gustav Ullrich GmbH
Landauer Str. 45
76855 Annweiler, Germany
☎ +49 6346 309-0
☎ +49 6346 309-480
✉ info@stabila.de
www.stabila.com

10

YEAR WARRANTY*

* Written guarantee for STABILA spirit levels

In addition to the statutory rights to which the purchaser is entitled and which are not limited by this guarantee, STABILA guarantees the instrument against defects and the absence of the warranted characteristics resulting from material or manufacturing defects for a period of 10 years from the date of purchase. This guarantee is valid worldwide. STABILA has the right to decide at its own discretion whether the defects will be rectified by being repaired or whether the instrument will be replaced. STABILA accepts no further liability. Defects caused by improper handling or modifications to the instrument undertaken by the purchaser or third parties invalidate the guarantee. No liability is accepted for normal wear and tear and minor defects which do not detract from the function of the instrument. Please send your claims under the guarantee along with proof of purchase to the guarantor.

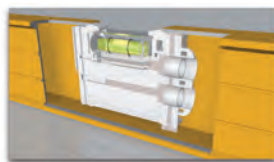

(schematic diagram)

Long-term precision from STABILA

The unique installation technology ensures long-term accuracy. In a special casting process, the components of the spirit level are firmly bonded forever. You can trust that your spirit level will maintain its accuracy for life. It remains accurate, just as it was on the first day. No readjustments, no doubts. Always accurate measurements – even under the most difficult construction site conditions.



See all products at
www.stabila.com



[www.youtube.com/
StabilaTools](http://www.youtube.com/StabilaTools)



[www.facebook.com/
StabilaTools](http://www.facebook.com/StabilaTools)



Our technical support team will assist you with all questions relating to product selection and use: Phone +49 6346 309-0. You can of course also e-mail us at info@stabila.de.