

DIN 41651 Flat Cable Connector System Box Headers without Locking

Pitch 2.54 mm, IDC



SPECIFICATION:



Operating Current (Nom.): 3 A
 Operating Temperature: -40°C to 105°C
 Insulation Resistance (Min.): 1000 MΩ
 Contact Resistance (Max.): 20 mΩ
 Dielectric Strength: 1,000 Vac

MATERIAL:

Material (Terminal): brass, gold plated
 Material (Housing): PBT
 Flammability Class: UL 94 V-0
 Material (Contact Area): brass, gold plated

HANDLING:

Packaging: tray

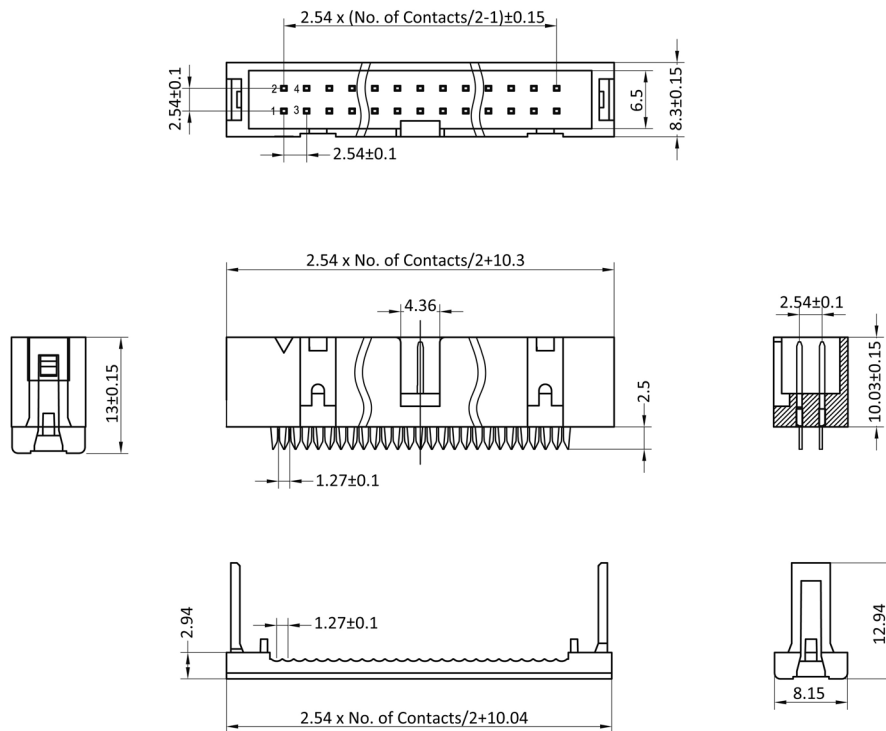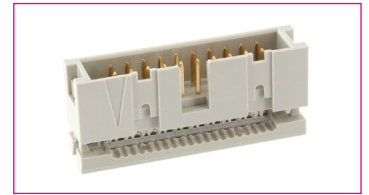

Order Information

Identifier:	No. of Contacts:	Contact Plating:
WSK	#	#
Box header pitch 2.54 mm, IDC	10: 2 x 5	G: gold plated *
	14: 2 x 7	A: 5 μ" gold
	16: 2 x 8	B: 10 μ" gold
	20: 2 x 10	
	26: 2 x 13	
	34: 2 x 17	
	40: 2 x 20	
	50: 2 x 25	
	64: 2 x 32	

* = Standard