

SPECIFICATION:

Operating Current (Nom.): 1.5 A
 Operating Temperature: 0°C to 70°C
 Insulation Resistance (Min.): 500 MΩ
 Contact Resistance (Max.): 40 mΩ
 Dielectric Strength: 1,000 Vac

MATERIAL:





Material (Terminal): phosphor bronze, nickel plated and gold plated
 Material (Housing): FR52 high temperature
 Material (Shield): brass, nickel plated
 Material (Contact Area): phosphor bronze, gold plated

HANDLING:

Processing: wave soldering, reflow soldering
 Packaging: tray
 Packing Unit: 15 piece(s)

TOLERANCE:

.X: ± 0.38
 .XX: ± 0.25

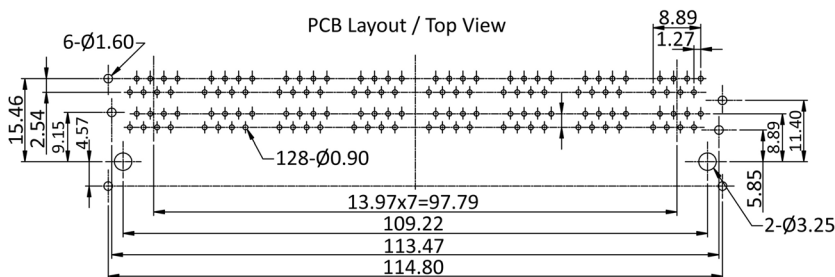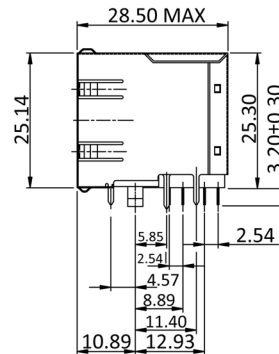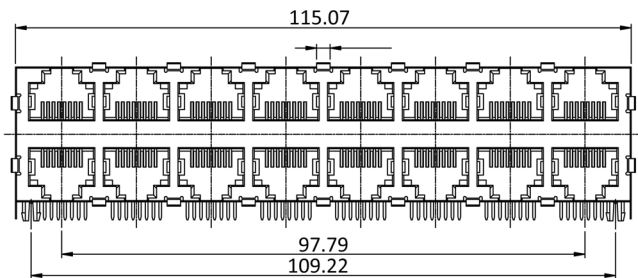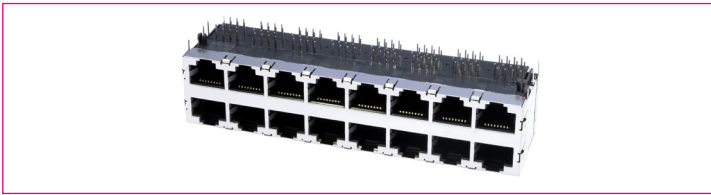

Order Information

Identifier:
3022S8

Modular jack 16xRJ45 shielded, pcb mount

Contact Plating:
#

empty: 6 μ" gold *
B: 15 μ" gold
C: 30 μ" gold
D: 50 μ" gold

* = Standard