

Patch Cables Cat.6

PiMF S/FTP



SPECIFICATION:

Frequency: 300 MHz




MATERIAL:

Material (Sheath): PVC
 Material (Shield): copper alloy, nickel plated
 Material (Contact Area): copper alloy, 3 μ" gold plating

HANDLING:

Packaging: Bag, single-packed

**RoHS
COMPLIANT**

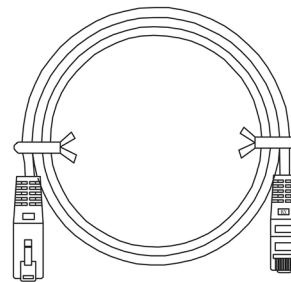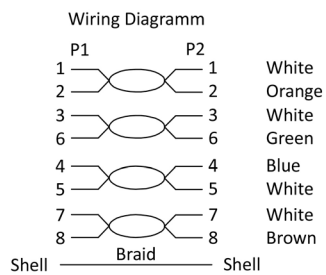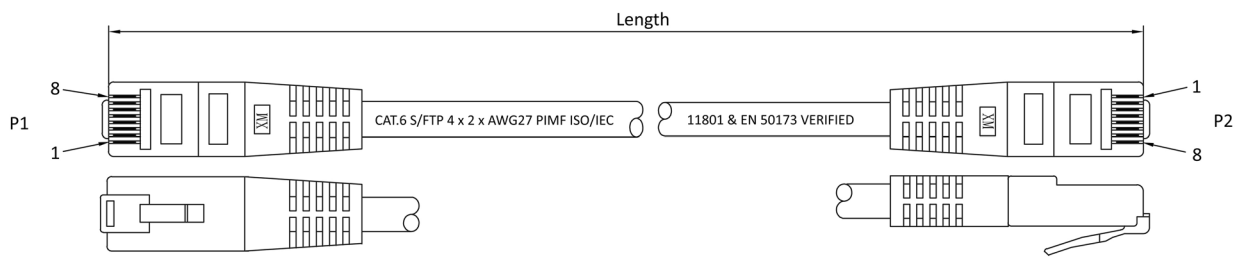

Order Information

Identifier:	Length:	Colour:
F6TP	#	#
Patch Cord S/FTP Cat.6 shielded	0,25: 0.25 m	GR: grey
	0,5: 0.5 m	RT: red
	1: 1.0 m	BL: blue
	2: 2.0 m	GE: yellow
	3: 3.0 m	GN: green
	5: 5.0 m	SW: black
	7: 7.0 m	
	10: 10.0 m	
	15: 15.0 m	
	20: 20.0 m	