

SPECIFICATION:

Operating Current (Nom.): 1.5 A
 Operating Temperature: 0°C to 70°C
 Insulation Resistance (Min.): 500 MΩ
 Contact Resistance (Max.): 40 mΩ
 Dielectric Strength: 1,000 Vac

MATERIAL:







Material (Terminal): phosphor bronze, nickel plated and gold plated
 Material (Housing): PBT
 Material (Shield): brass, nickel plated
 Material (Contact Area): phosphor bronze, gold plated

HANDLING:

Flammability Class: UL 94 V-0
 Packaging: tray

TOLERANCE:

.X: ± 0.38
 .XX: ± 0.25

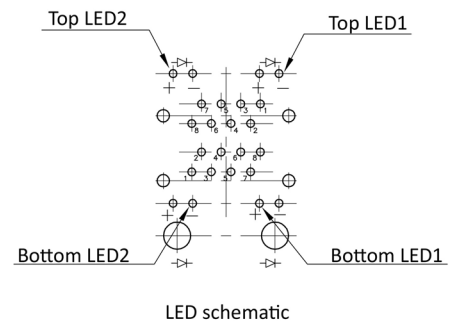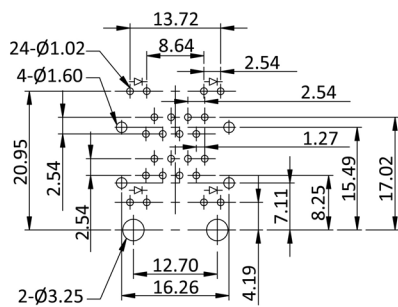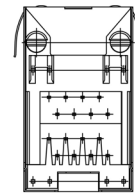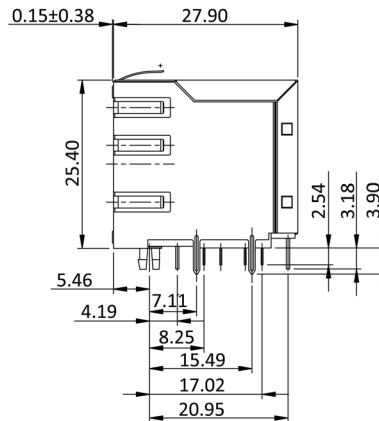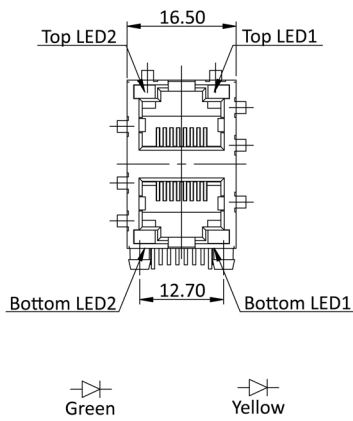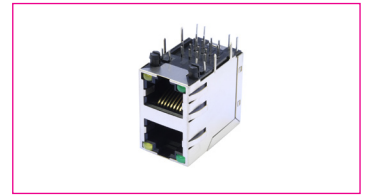

Order Information

Identifier:	Contact Plating:	LED 2 (left) / LED 1 (right):
MDFL188	#	#
Modular jack 2xRJ45 shielded, pcb mount	1: 3 μ" gold *	0: No LED
	2: 6 μ" gold	1: green / yellow *
		2: yellow / green
		3: green / green
		4: green / red

* = Standard