

**Industrial Ethernet
IE-BSS-VAPM-24V**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com



PushPull Power plug-in connector according to PROFINET specification

General ordering data

Type	IE-BSS-VAPM-24V
Order No.	2493480000
Version	Power connector, Flange, PROFINET, Set of flanges
GTIN (EAN)	4050118522143
Qty.	1 pc(s).

**Industrial Ethernet
IE-BSS-VAPM-24V**

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Technical data
Dimensions and weights

Length	66 mm	Length (inches)	2.598 inch
Width	46 mm	Width (inches)	1.811 inch
Net weight	54 g		

Temperatures

Operating temperature, max.	70 °C	Operating temperature, min.	-40 °C
Operating temperature	-40 °C...70 °C	Storage temperature	
Installation temperature			

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
------------	----------------

General data

Colour	Silver grey	Connection 1	Tension clamp
Contact material	Copper alloy	Contact surface	Gold over nickel
Housing main material	Zinc diecast, nickel-plated	No. of poles	5
Plugging cycles	≥ 100	Pollution severity	2
Protection degree	IP67	Sealing material	NBR
Type of interlock	Push Pull	Type of mounting	4 screws
UL 94 flammability rating	V-2	Wire connection cross section, finely stranded, max.	2.5 mm ²
Wire connection cross-section, finely stranded, min.	0.75 mm ²		

Electrical properties

Current-carrying capacity at 50 °C	16 A	Operating voltage	24 V
------------------------------------	------	-------------------	------

Standards

Connector standard	in accordance with PROFINET specification	Certificate No. (UR)	E92202
--------------------	---	----------------------	--------

Classifications

ETIM 6.0	EC001121	eClass 6.2	27-25-05-04
eClass 9.0	27-44-03-90	eClass 9.1	27-44-03-90

Approvals

Approvals



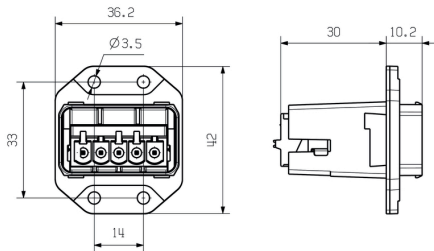
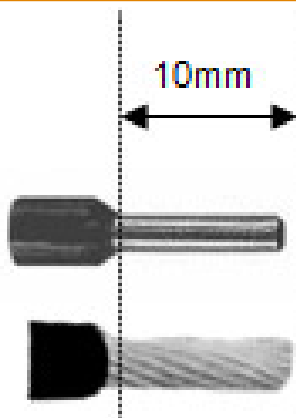
ROHS	Conform
------	---------

Downloads

Engineering Data	STEP
------------------	----------------------

**Industrial Ethernet
IE-BSS-VAPM-24V**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Drawings**Dimensioned drawing****Drawing**

We recommend using 10-mm-long wire-end ferrules