


Spare Fuse for VC200 series, 12 A/1000 V, 6 x 32 mm

Description

- Fast acting, high breaking capacity
- 6 x 32 mm physical size
- Ceramic tube, Silver plated copper cap construction
- Designed to UL 248-1
- Lead free and Halogen free material



Drawing (Unit: mm)

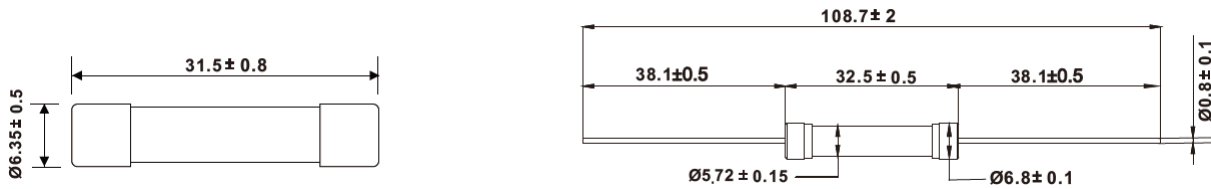

Note: 10 A-50 A for $\text{Ø} 1.0 \pm 0.1$ mm needle cap

Technical Data

Rated Voltage: 1000 V AC/DC

Rated Current: 12 A

Breaking Capacity: 10 kA

Typical Pre-Arcing I^2t ($A^2\text{Sec}$)³: 135

Electrical Characteristics

Rated Current	1.0 In	2.5 In
200 mA~12 A	4 hours min.	120 sec max.

Time-Current Curve

