

Data Sheet

320pcs Crimp blade and Receptacle connectors pair set with insulators-assortment


Household appliances use crimp blade and receptacle connectors from 2.8mm to 6.3mm, which are widely available. This practical range consists of the most common blade connectors, soft insulating sleeves and hard plastic protecting boots - ideal for repair and maintenance. The compilation includes the cross sections from 0.5 mm² to 2.5 mm² for fine and superfine conductors. Connection angle 180 °. Material: electrolytic copper.

Contents:

- 2.8 x 0.8 blade connector , cross section 0.5~1.0mm² - 30pcs
- 2.8 x 0.8 receptacle connector, cross section 0.5~1.0mm² - 30pcs
- 4.8 x 0.8 blade connector, cross section 1.5~2.5mm² - 25pcs
- 4.8 x 0.8 receptacle connector, cross section 1.5~2.5mm² - 25pcs
- 6.3 x 0.8 blade connector, cross section 1.5~2.5mm² - 18pcs
- 6.3 x 0.8 receptacle connector, cross section 1.5~2.5mm² - 18pcs
- PVC cover for 2.8 mm connector, Red, Blue, Transparent @ 25pcs
- PVC cover for 4.8mm connector, Red, Blue, Transparent @ 18pcs
- PVC cover for 6.3mm connector, Red, Blue, Transparent @ 15pcs




Blade and Receptacle connector

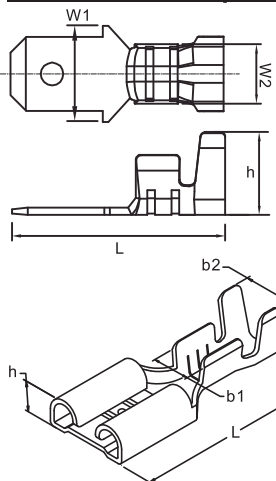

Tab (mm)	Cross section (mm ²)	L (mm)	h (mm)	W1 (mm)	W2 (mm)
2.8 x 0.8	0.5 - 1.0	16.0	4.7	2.8	2.9
4.8 x 0.8	1.5 - 2.5	17.0	4.7	4.8	3.5
6.3 x 0.8	1.5 - 2.5	20.0	4.5	6.3	3.8

Receptacle (mm)	Cross section (mm ²)	L (mm)	h (mm)	b1 (mm)	b2 (mm)
2.8 x 0.8	0.5 - 1.5	15.8	2.0	2.3	3.8
4.8 x 0.8	1.5 - 2.5	15.5	2.4	4.3	6.0
6.3 x 0.8	1.5 - 2.5	19.0	2.8	4.5	7.2

PVC insulating sleeve

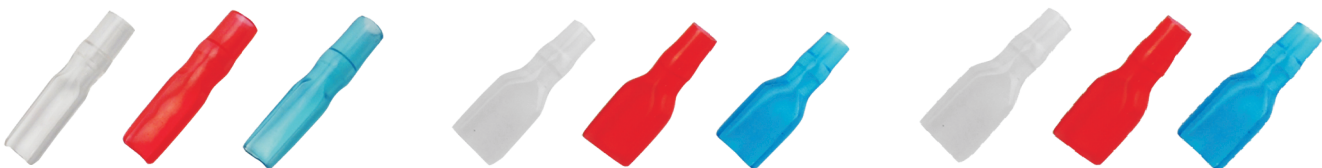

Suitable for tab(mm)	L (mm)	L1 (mm)	d1 (mm)	d2 (mm)	w (mm)
2.8 x 0.8	23.0 ± 2.0	15.5 ± 1.5	4.0	∅3.0	1.8
4.8 x 0.8	23.0 ± 2.0	15.5 ± 1.5	5.0	∅3.0	2.3
6.3 x 0.8	25.0 ± 2.0	18.0 ± 2.0	8.0	∅3.5	3.5

