


Item no.: T1711C002

Data Sheet

3200pcs Cable-ferrules-assortment

The assortment consists of uninsulated and insulated wire end ferrules in a practical transparent assortment box. The assortment includes various wire end ferrules from 0.5 mm² to 10 mm² for fine and finest wires. Simple insulation for splice-free cable entry. Temperature resistant up to 75/120°C. Galvanic tinned for protection against corrosion. Material: copper and plastic, surface finishing: tinned.

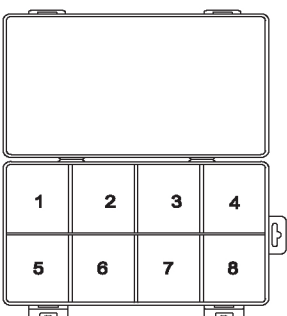

Section	Contents	pcs
1	Non-Insulated Cable Ferrules, 0.5mm ² x 8mm	700
	Non-Insulated Cable Ferrules, 0.75mm ² x 8mm	700
2	Non-Insulated Cable Ferrules, 1.0mm ² x 6mm	700
	Non-Insulated Cable Ferrules, 1.5mm ² x 8mm	700
3	Insulated Cable Ferrules, 0.5mm ² x 8mm	60
	Insulated Cable Ferrules, 0.75mm ² x 8mm	60
4	Insulated Cable Ferrules, 6.0mm ² x 12mm	30
	Insulated Cable Ferrules, 1.0mm ² x 8mm	60
5	Insulated Cable Ferrules, 1.5mm ² x 8mm	60
	Insulated Cable Ferrules, 10mm ² x 12mm	30
6	Insulated Cable Ferrules, 4.0mm ² x 9mm	50
	Insulated Cable Ferrules, 2.5mm ² x 8mm	50


Non-Insulated cable ferrules



Material: Tinned Copper
 Operating Voltage: 600V max.
 Operating Temperature: 120°C max.

Wire Range (mm ²)	L(mm)	D(ømm)	D1(ømm)	D2(ømm)
0.5	8.0	3.1	1.0	1.3
0.75	8.0	2.3	1.2	1.5
1.0	6.0	2.5	1.4	1.7
1.5	8.0	2.8	1.7	2.0

 Insulated cable ferrules



Insulator Material: Vinyl
 Terminal Material: Tinned Copper
 Operating Voltage: 600V max.
 Operating Temperature: 75°C max.

Wire Range (mm ²)	L(mm)	L1(mm)	L2(mm)	D(ømm)	D1(ømm)	D2(ømm)	code (DE)
0.5	14.0	6.0	8.0	2.6	1.0	1.3	Orange
0.75	14.0	6.0	8.0	2.8	1.2	1.5	White
1.0	14.0	6.0	8.0	3.0	1.4	1.7	Yellow
1.5	14.0	6.0	8.0	3.5	1.7	2.0	Red
2.5	14.0	6.0	8.0	4.2	2.2	2.6	Blue
4	18.0	9.0	9.0	4.8	2.8	3.2	Grey
6	20.0	8.0	12.0	6.3	3.5	3.9	Black
10	22.0	10.0	12.0	7.6	4.5	4.9	Ivory