


Data Sheet

LiY-wire 0.22 sqmm, 25 m, white

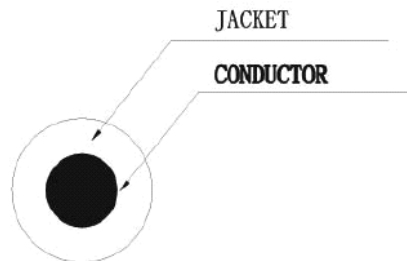

Technical data

Insulation material (with thickness): PVC 0.34mm

Jacket diameter: 1.2 +/- 0.1 mm

Jacket colour: White

Conductor construction: 7 / 0.2 mm

Length: 25m

Conductor material : tinned-copper

Core diameter 0.2mm

Conductor AWG: 1 x 0.22 mm²

Conductor resistance (Ohm/km): Max 87 ohm/km

Insulation resistance: Min 200M ohm x km

Maximum dielectric strength: 1500V / AC

Temperature range: -20 to +70 C

Rated voltage: 48V

Conductor structure: twisted

Type of flammability: IEC60332-1/EN50265-2-1