

**SPECIFICATION:**

Operating Voltage (Max.): 250 V  
 Operating Current (Nom.): 2.5 A  
 Operating Temperature: -25°C to 85°C  
 Insulation Resistance (Min.): 1000 MΩ  
 Contact Resistance (Max.): 10 mΩ  
 Dielectric Strength: 1,000 Vac

**MATERIAL:**





Material (Housing): nylon 66  
 Flammability Class: UL 94 V-2

**HANDLING:**

Packaging: bulk

**TOLERANCE:**

.X: ± 0.35  
 .XX: ± 0.30

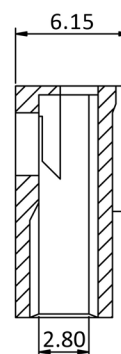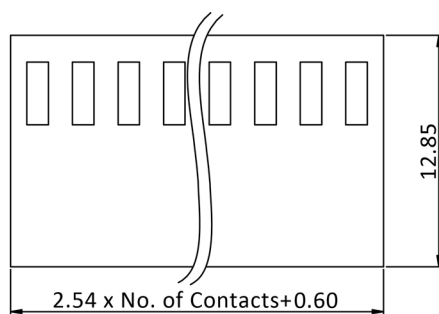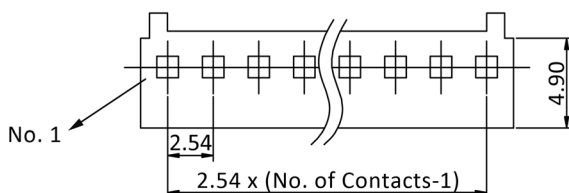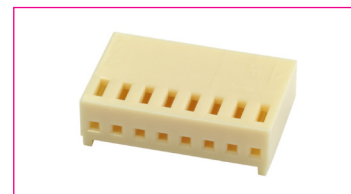

**Order Information**

Identifier:

CV

Housing series CV pitch 2.54 mm single row

No. of Contacts:

#

2: 1 x 2

3: 1 x 3

4: 1 x 4

:

20: 1 x 20