

SPECIFICATION:

Operating Voltage (Max.): 250 V
 Operating Current (Nom.): 3 A
 Operating Temperature: -25°C to 85°C
 Insulation Resistance (Min.): 1000 MΩ
 Contact Resistance (Max.): 20 mΩ
 Dielectric Strength: 800 Vac

MATERIAL:



Material (Housing): Noryl
 Flammability Class: UL 94 V-1

HANDLING:

Packaging: bulk

TOLERANCE:

.X: ± 0.35
 .XX: ± 0.25

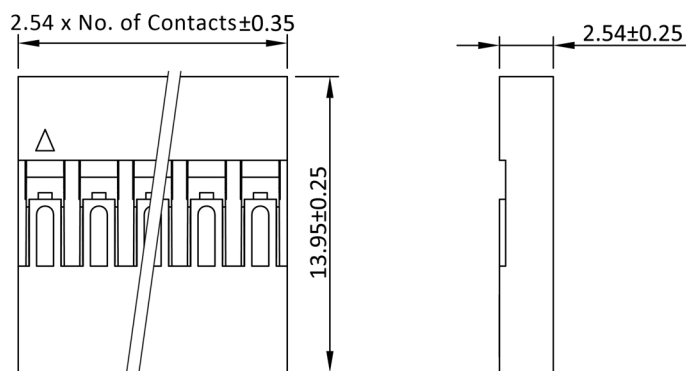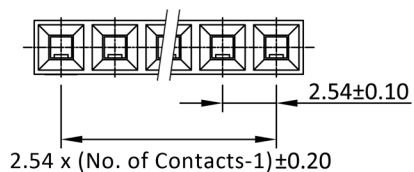

Order Information

Identifier:	No. of Contacts:
CG	#
Housing series CG pitch 2.54 mm single row	1: 1 x 1
	2: 1 x 2
	3: 1 x 3
	:
	40: 1 x 40