


TECHNICAL SPECIFICATIONS

Housing:	Polycarbonate
Contacts:	Copper
Contact Plating:	Silver
Spring:	Stainless Steel
Flammability Rating:	UL94 V-0
Operating Temperature Range:	-20°C to 105°C
Insulation Withstanding Test:	2200 VDC
Vibration Resistance:	Excellent
Mating Cycles:	10.000 (For disconnect use only)







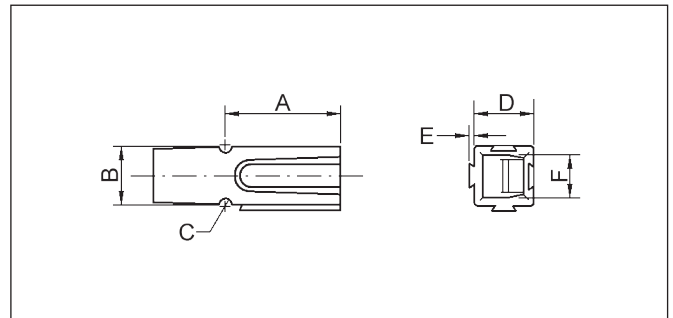

Features:

- Cost Effective Reliability
- Genderless Connectors
- Provides 600 Volts Continuous AC or DC



Model:	A	B	C	D	E	F
120 A	42,90	22,60	2,50	22,30	1,50	15,20

Order Codes:

120A	Part No:	Description:	Colour:	
Housings:	1130-0102-01	ET1321	Blue	
	1130-0102-02	ET1321G1	Black	
	1130-0102-03	ET1321G2	White	
	1130-0102-04	ET1321G3	Red	
	1130-0102-05	ET1321G4	Green	
Contact pins:	1130-0112-01	ET1319-2	2 AWG	
	1130-0112-02	ET1319-4	4 AWG	
	1130-0112-03	ET1319-6	6 AWG	

