

Connectors for LED Illumination Terminal Blocks Pitch 4.0 mm

Height 3.8 mm SMT



SPECIFICATION:

Operating Voltage (Max.): 320 V
 Operating Current (Nom.): 9 A
 Operating Temperature: -45°C to 105°C
 Insulation Resistance (Min.): 1000 MΩ
 Contact Resistance (Max.): 20 mΩ
 Soldering Heat (Max.): 260 °C for 5 s

MATERIAL:



Material (Terminal): copper alloy, tin plated
 Material (Insulation): thermoplastic
 Material (Contact Area): copper alloy, tin plated

HANDLING:

Packaging: taped

TOLERANCE:

.X: ± 0.38
 .XX: ± 0.25

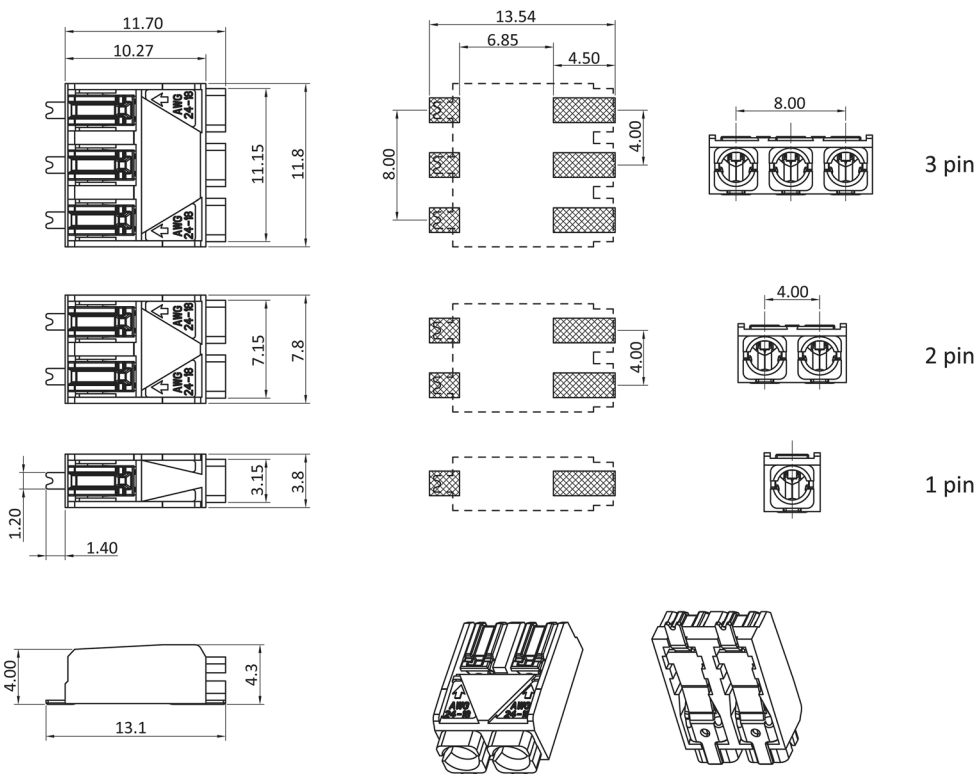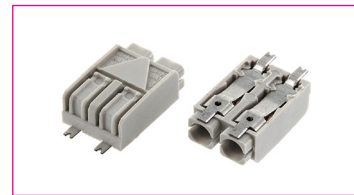

Order Information

Identifier:	Version:	No. of Contacts:	Colour:
LEDV10	BU	#	GR
LED Terminal Block pitch 4.0 mm height 3.8 mm SMT	female	1: 1 poles	grey
		2: 2 poles	
		3: 3 poles	