






S2R BATON II

RECHARGEABLE VARIABLE-OUTPUT
SIDE-SWITCH LED FLASHLIGHT

MAX OUTPUT	MAX RUNTIME	MAX THROW
		
1150 lumens	60 days	135 meters

* This information is for market reference only. Please do not make it public.



TIR Lens

S2R BATON II

RECHARGEABLE VARIABLE-OUTPUT SIDE-SWITCH LED FLASHLIGHT



APPLICATION FIELDS

outdoors & household

UPC:

6926540918831

DESCRIPTION

The S2R Baton II is the upgraded version of the popular S2R Baton predecessor. It has a compact build (5% shorter than S2R Baton) for easy grip and portability. The light can produce a maximum output of 1,150 lumens including an upgraded TIR lens that produces a perfectly balanced beam. It has several modes to choose from including three standard modes, turbo, moonlight, and strobe. The S2R Baton II features a battery indicator located on the side switch so you always know when to charge. It boasts a new MCC II magnetic charging system to ensure faster charging in a smaller form factor. The S2R II also features a dual direction pocket clip for enhanced everyday carry.



S2R BATON II

RECHARGEABLE VARIABLE-OUTPUT SIDE-SWITCH LED FLASHLIGHT



FEATURES

- CW LED with a maximum output of 1,150 lumens.
- Includes a 3200mAh 18650 rechargeable lithium battery which is charged magnetically through the tailcap charging cable.
- Features a battery indicator located on the side switch so you know when to charge. Indicator glowing green (Battery remaining $\geq 70\%$), indicator glowing yellow (Battery remaining 15-70%), indicator glowing red (Battery remaining $\leq 15\%$).
- Portable faster charging MCC II USB charging cable provided in the package.
- Brand-new TIR lens design producing a perfectly balanced beam.
- Flat tailcap with a strong magnet allowing the ability to use as a hands-free work light.
- Multi-function side switch with five brightness levels, plus a strobe mode.

OUTPUT

FL1 STANDARD	Mode 1	Mode 2	Mode 3	Mode 4	Mode 5
	1,150 ± 400 lumens	400 lumens	120 lumens	15 lumens	0.5 lumens
	2+230 minutes	4 hours	14 hours	100 hours	60 days
	135 Meters	80 Meters	45 Meters	15 Meters	N/A
	4,600 cd	1,600 cd	510 cd	60 cd	N/A

LIGHT SOURCE

Luminus SST-40 LED

DIMENSIONS

Length: 3.94in/100mm

Head Diameter: 0.91in/23mm

Body Diameter: 0.91in/23mm

WEIGHT

98.5 g (including battery and pocket clip)

BODY MATERIAL

AL6061-T6 Aluminum alloy, (Type III) hard anodized

BATTERY SOURCE

Customized 3200mAh 3.6V 18650 Battery

WARRANTY


5 Year Warranty

Visit: <https://olightworld.com/olight-warranty>

ACCESSORIES

Customized 3200 mAh 3.6V 18650 Battery×1
MCC II charging cable×1
User manual×1 Pouch×1
Blue pocket clip×1(installed on the flashlight)
Black pocket clip×1(spare, inside the package)
Lanyard (including tethering tool)×1

WATERPROOF IPX8

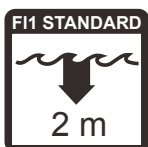

DROP TEST



COMPLIANCE



The above data are test results retrieved according to ANSI NEMA FL 1-2009 standards.