


Datasheet

Item no. 1909644, 1909645, 1909646, 1909647, 1909648, 1909649, 1909650



CONSTRUCTION DRAWING:

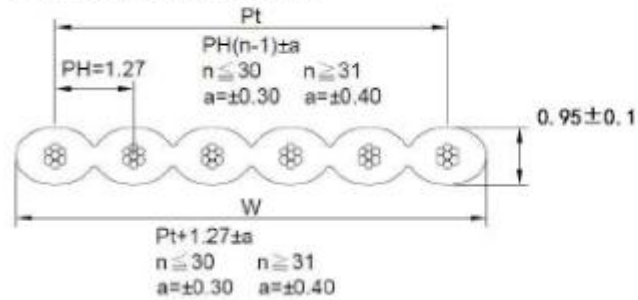

n = Number of conductor

Flat Ribbon Cable

American Wire Gauge:	28AWG
Cable Shape:	Ribbon
Capacitance:	49.2 pF/m
Characteristic Impedance:	105 Ohm
Conductor Strand Type:	Stranded
Core Strands:	7x0.127 mm
Number of Strands:	7
Sheath Colour:	Multicoloured
Operating Temperature Range:	-20 to +105° C
Pitch:	1.27mm
Reel Length:	30 m
Voltage Rating:	300V dc
Standards Met:	UL20130

Datasheet

Item no. 1909644, 1909645, 1909646, 1909647, 1909648, 1909649,
1909650

BN	Number of ways	Reel length
1909644	10 pins	30 M
1909645	20 pins	30 M
1909646	26 pins	30 M
1909647	30 pins	30 M
1909648	34 pins	30 M
1909649	40 pins	30 M
1909650	60 pins	30 M