


Datasheet

Item no. 1909651, 1909652, 1909653, 1909654, 1909655, 1909656, 1909657



CONSTRUCTION DRAWING:

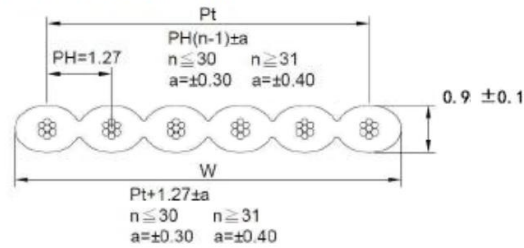

n = Number of conductor

Flat Ribbon Cable

American Wire Gauge:	28AWG
Cable Shape:	Ribbon
Capacitance:	49.2 pF/m
Characteristic Impedance:	105 Ohm
Conductor Strand Type:	Stranded
Core Strands:	7x0.127 mm
Number of Strands:	7
Sheath Colour:	Grey
Operating Temperature Range:	-20 to +105° C
Pitch:	1.27mm
Reel Length:	30m
Voltage Rating:	300V dc
Standards Met:	UL20130

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com).

All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing.

Datasheet

Item no. 1909651, 1909652, 1909653, 1909654, 1909655, 1909656, 1909657

BN	Number of ways	Reel length
1909651	10 pins	30 M
1909652	14 pins	30 M
1909653	16 pins	30 M
1909654	20 pins	30 M
1909655	26 pins	30 M
1909656	34 pins	30 M
1909657	64 pins	30 M